

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0395211012
Status: Active
Overview: Eurostyle™ Terminal Blocks
Description: 5.00mm Pitch Eurostyle™ Vertical PCB Header, 12 Circuits

Documents:
[3D Model](#) [Product Specification PS-39500-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
UL E48521


General
Product Family Terminal Blocks
Series 39521
Application N/A
Component Type PCB Header
Overview Eurostyle™ Terminal Blocks
Product Name ESE, Eurostyle™ Pluggable
Type Euro Block
UPC 822350476492

Physical
Circuits (Loaded) 12
Entry Angle N/A
Lock to Mating Part Yes
Number of Rows 1
Orientation Vertical
PC Tail Length 3.90mm
PCB Thickness - Recommended 3.20mm
Panel Mount No
Pitch - Mating Interface 5.00mm
Pitch - Termination Interface 5.00mm
Polarized to Mating Part Yes
Shrouded Closed Ends
Stackable No
Temperature Range - Operating -40°C to +105°C
Wire Size AWG N/A

Electrical
Current - Maximum per Contact 15.0A
Voltage - Maximum 300V

Material Info

Reference - Drawing Numbers
Product Specification PS-39500-001-001
Sales Drawing SD-39521-002

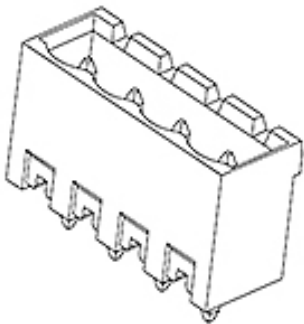

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant	China RoHS
-----------------------------	-------------------

REACH SVHC
Not Contained Per - ED/108/2014 (17 Dec 2014)
Halogen-Free Status
Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[39521](#) Series

Mates With
[39520](#) Horizontal Plug, [39523](#) Vertical Plug,
Most 5.00mm Pitch Industry Standard Plugs

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION