

DESCO INDUSTRIES INC. Technical Bulletin TB-7056

Material Safety Data Sheet


Material Safety Data Sheet maybe used to comply with EC, according to 91/155EC and ANSI Standard Z400.1-1998
Date: January 26, 2004

NFPA Designation 704

Degree of Hazard

4 = Extreme
3 = High
2 = Moderate

1 = Slight
0 = Insignificant

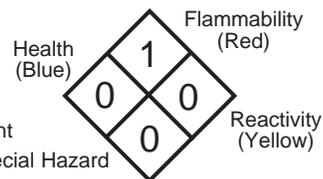

Trustat® B80 Vinyl Mats

SECTION 1 - IDENTIFICATION OF THE PRODUCT AND OF THE ENTERPRISE

Product Name/Identity: Trustat® B80 Vinyl Mats
Manufacturer: Desco Industries Inc.
Address: One Colgate Way,
Canton, MA 02021
U.S.A.
Telephone: (781) 821-8370
Emergency Number: (781) 821-8370
Date Prepared: 2013-01-25

SECTION 2 - HAZARDOUS INGREDIENTS

Hazardous Components None

SECTION 3 - PHYSICAL AND CHEMICAL CHARACTERISTICS

Boiling Point:	N/A	Specific Gravity:	0.35
Vapor Pressure:	N/A	Percentage Volatile:	N/A
Vapor Density:	N/A	Evaporation Rate:	N/A
Solubility in Water:			N/A
Appearance and Odor:	Cellular Vinyl Mat, Characteristic Vinyl Odor		

SECTION 4 - PHYSICAL HAZARDS

Stability:	Stable
Conditions to Avoid:	None
Incompatible Materials:	None
Hazardous Decomposition Products:	Carbon Monoxide and Hydrogen Chloride when burning
Hazardous Polymerization:	Will Not Occur

SECTION 5 - HEALTH HAZARDS

Threshold Limit Value	None
Effects of Overexposure:	N/A
Emergency and First Aid Procedures:	N/A

SECTION 6 - HEALTH HAZARDS

Respiratory Protections:	Not Required
Ventilation:	Not Required
Gloves:	Not Required
Eye Protection:	Not Required

SECTION 7 - PRECAUTIONS FOR SALE HANDLING AND USE

Precautions to be Taken in Handling and Storing	None
Steps to Be taken in Case Material is Released or Spilled	None
Waste Disposal Method	Incinerate or landfill according to local, state, and federal regulations
Transportation:	None

OTHER INFORMATION

Further Information None Known

Disclaimer

The information given in this publication has been worked up to the best of the knowledge of Desco Industries Inc, as well as taking into consideration the applicable laws and regulations. We cannot anticipate all conditions under which this information and our products or the products of the manufacturers in combination with our products may be used. We accept no responsibility for the results obtained by the application information or the safety and suitability of our product or product combination with other products. Users are advised to make their own tests to determine the safety and suitability of each such product or product combination for their own purposes. Unless otherwise agreed in writing, we sell the products without warranty, and buyers end users assume responsibility and liability for loss or damage arising from the handling and use of our products, whether used alone or in combination with other products.

N/A = Not Applicable; NE = None Established