


Ceramic, Safety, C900_Y, 100 pF, 5%, SL, Lead Spacing = 5mm

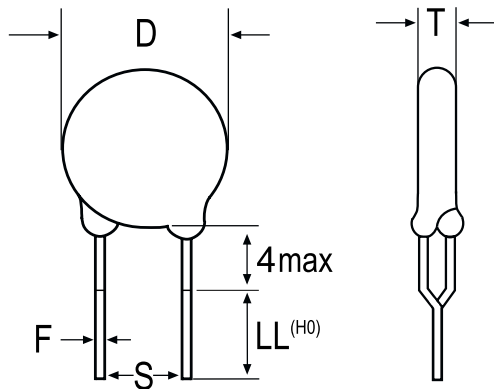

Dimensions

D	10mm MAX
T	5mm MAX
S	5mm +/-0.8mm
LL	4.5mm +/-1mm
F	0.55mm +/-0.1mm

Packaging Specifications

Packaging:	Bulk
Packaging Quantity:	500

General Information

Style:	Radial Disc
Series:	C900_Y
RoHS:	Yes
Termination:	Tin
Failure Rate:	N/A
Safety Class:	X1/Y2
Approvals:	UL, ENEC, CSA
Halogen Free:	Yes

Specifications

Capacitance:	100 pF
Capacitance Tolerance:	5%
Voltage:	400 VAC (X), 250 VAC (Y)
Dielectric Withstanding Voltage:	2,600 V
Temperature Range:	-40/+125C
Temperature Coefficient:	SL
Insulation Resistance:	10 GOhms
Quality Factor:	1000