




STAKEI 5 grau/grey

Industrial Connectors:Rectangular connectors ST-series:Panel-mounted socket

Product description

Description	Panel-mounted connector, not assembled with added contacts and added gasket
Type	STAKEI 5 grau/grey
Order No.	931 694-106
Type of contact	female
Number of contacts	5 + PE
Conductor size	max. 1 mm ²
Housing Color	grey
Contact bearer color	black

Drawing

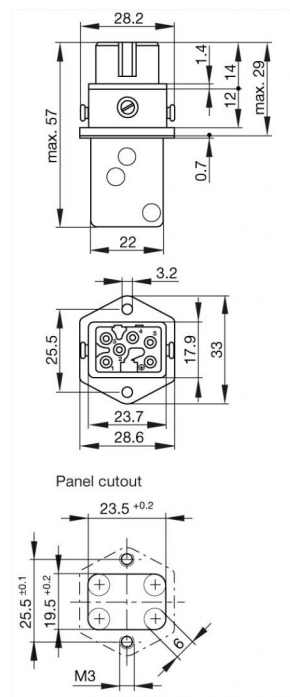

Technical data

Pin dimensions	1.6 mm
Rated voltage	AC 400 V / DC 250 V
Rated current	DC 10 A / AC 6 A
Contact resistance	≤ 10 mOhm
Type of termination	screws

Material

Contact material	Cu Zn
Contact surface material	Ag
Contact bearer material	PA

Housing material	PA
Environmental conditions	
Protection class (IEC 60529)	IP 54
Pollution severity	3
Temperature range	-30 °C to +90 °C
Inflammability class	
Housing	UL 94 HB
Contact bearer	UL 94 V-0
Approvals	
VDE	VDE
SEV	SEV
Packing unit	
Packaging unit	100 pieces
Scope of delivery and accessories	
Accessories to order separately	safety brackets STASI 3, order no. 732 045-001