

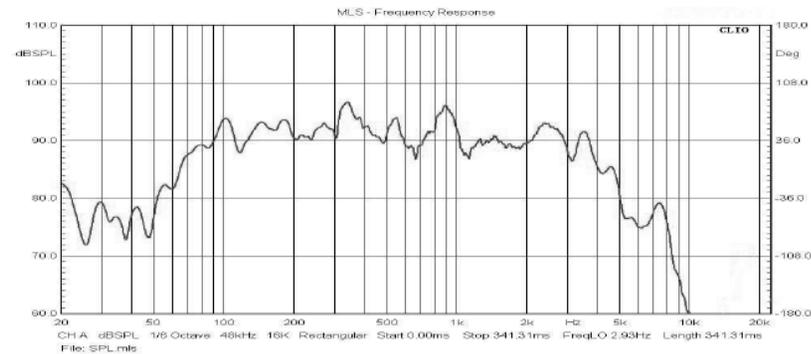


<b>Model Number:</b>	<b>55-2950</b>	
<b>GENERAL SPECIFICATIONS</b>		
Nominal Diameter:	8 inch	
Rated Impedance:	8 ohms	
Operating Bandwidth:	65Hz ~ 4.5KHz	
Power Handling Capacity:	100W RMS	
Sensitivity (1W/M):	94 dB	
Voice Coil Diameter:	2 inch	
<b>THIELE-SMALL PARAMETER</b>		
Resonance Frequency	Fs:	65 Hz
DC Resistance	Re:	7.2 ohm
Mechanical Q Factor	Qms:	2.5
Electrical Q Factor	Qes:	0.303
Total Q Factor	Qts:	0.27
Equivalent Cas air load	Vas:	46.4 liters
Coil Inductance	Le:	1.08 mH
Efficiency Bandwidth Product	EBP	214.52
Voice Coil Over Hang	X-max	3.5mm
<b>PHYSICAL INFORMATION</b>		
Basket:	Stamped Steel	
Magnet Type:	30 OZ	
Cone Material:	None press paper	
Surround:	cloth	
Dust Cap:	paper	
Damper:	cloth	

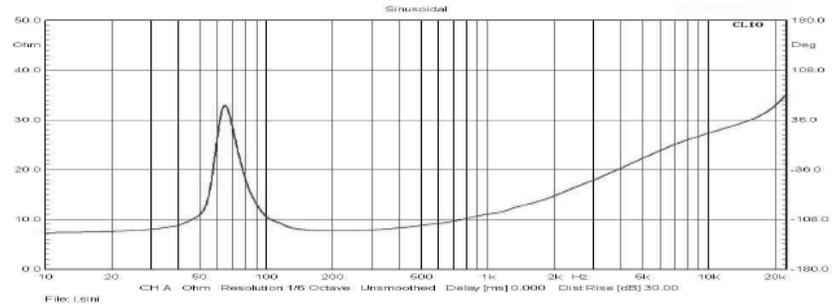

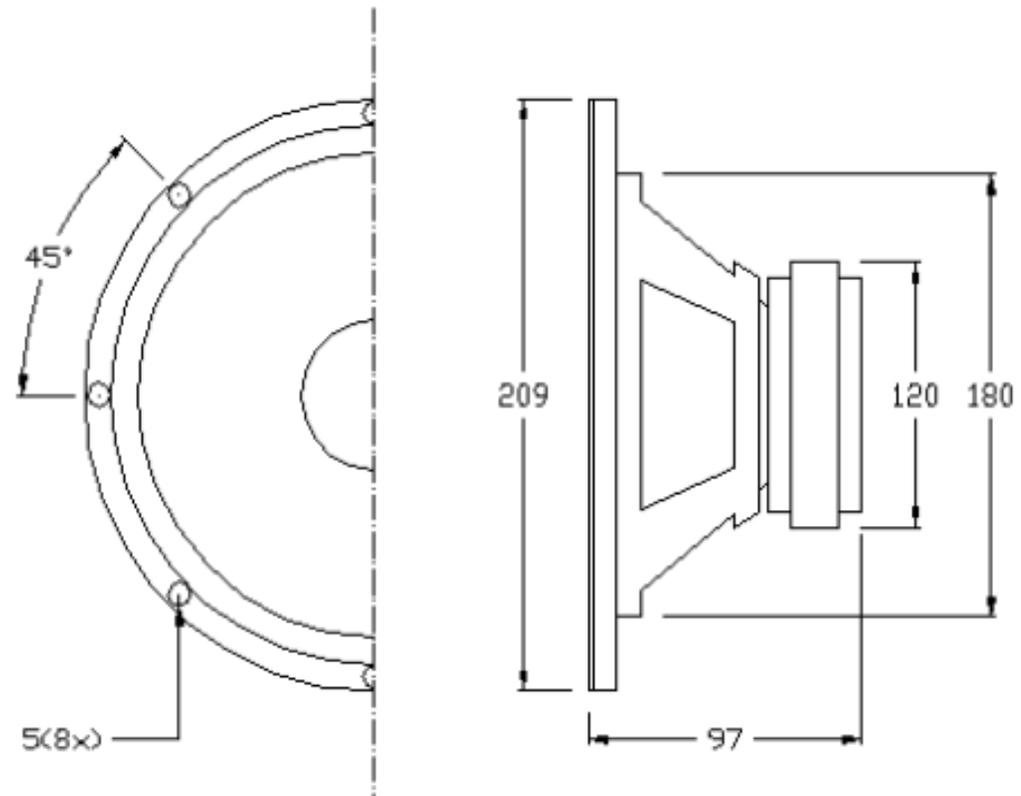

ALL DIMENSIONS ARE IN MILLIMETERS