
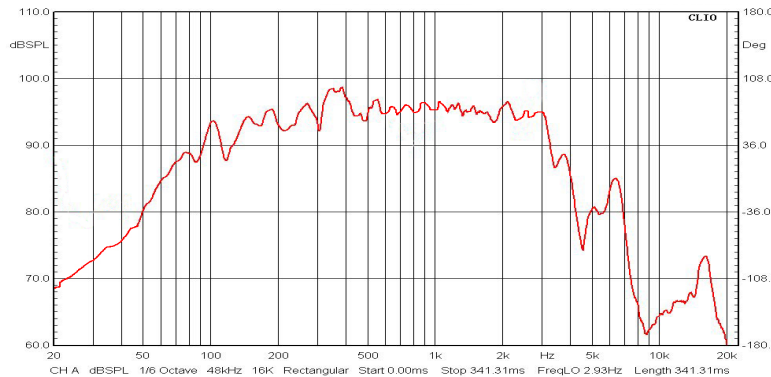


MCM CUSTOM AUDIO

Model Number:	55-3211	
GENERAL SPECIFICATIONS		
Nominal Diameter:	10 inch	
Rated Impedance:	4Ω	
Operating Bandwidth:	65 ~ 3KHz (-3dB)	
Power Handling Capacity:	150W RMS	
Sensitivity (1W/M):	95 dB (±3dB)	
Voice Coil Diameter:	2 inch	
THIELE-SMALL PARAMETERS		
Resonance Frequency	Fs:	38.6Hz
DC Resistance	Re:	3.4Ω
Mechanical Q Factor	Qms:	2.4907
Electrical Q Factor	Qes:	0.5516
Total Q Factor	Qts:	0.4516
Equivalent Cas air load	Vas:	82.27 L
Surface Area of Cone	Sd:	0.0346 m ²
Efficiency Bandwidth Product	EBP	70
Voice Coil Over Hang	X-max	5.0 mm
PHYSICAL INFORMATION		
Basket:	Stamped Steel	
Magnet Type:	40 Oz.	
Cone Material:	Non-pressed paper	
Surround:	cloth	
Dust Cap:	paper	
Damper:	cloth	

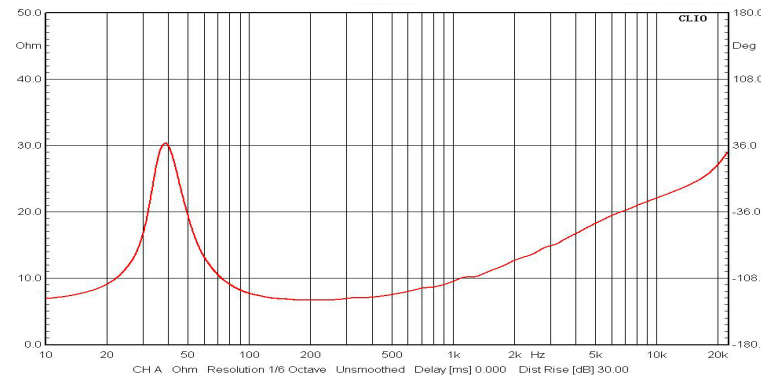

Date: 2012-7-3