




AGF 30

Industrial Connectors:Measuring and Testing Equipment:Alligator clips:4 mm system

Product description

| | |
|----------------|---|
| Description | Stainless steel alligator clip. The special shape allows clamping of both extremely fine and thick wires. Maximum bolt diameter 10 mm. 4 mm diameter socket connection and solder connection possible. Rust-proof, acid-proof and non-magnetic. |
| Type | AGF 30 |
| Order No. | 930 122-000 |
| System | 4 mm system |
| Clamping range | 10 mm |
| Housing Color | metallic |

Drawing

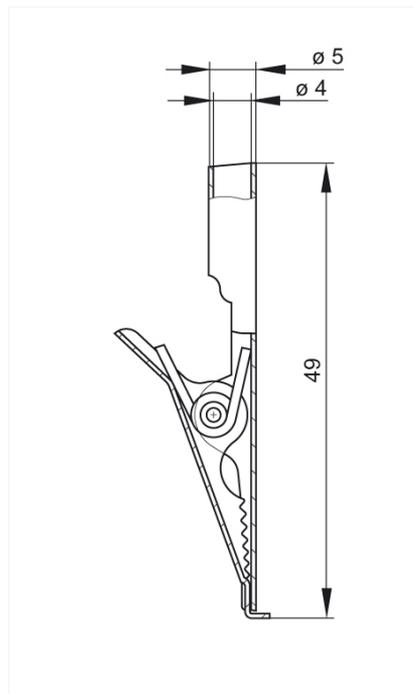

Technical data

| | |
|---------------------|---------------------|
| Type of contact | socket |
| Type of termination | 4 mm socket, solder |
| Rated voltage | DC 60 V |
| Contact resistance | 15 mOhm |

Material

| | |
|--------------------------|-----------------|
| Contact material | stainless steel |
| Contact surface material | stainless steel |
| Housing material | stainless steel |

Environmental conditions

Temperature range -25 °C to +100 °C

Inflammability class

Housing 94 HB