

SLR-3000

# PROSAFE RECHARGEABLE LED SITE LIGHT



3-6  
HOURS  
RUNTIME

25  
METRE  
BEAM RANGE

3000  
LUMENS  
OUTPUT

IPX4  
WATER  
RESISTANCE

- » 3000 Lumen 30W Samsung SMD LEDs
- » Powerful Li-ion battery with battery level indicator
- » Battery pack can easily be removed and used as a USB power bank
- » 50% dimming function to increase battery runtime
- » Built in aluminium heat sink
- » Anti-slip rubber grip handle
- » Adjustable head for light angle
- » Tough polycarbonate housing and stand
- » Acrylic LED diffuser for even light dispersion
- » Anti glare polycarbonate lens
- » SL-251 adjustable tripod available (holds 1 light)


**BATTERY** 7.4v 6600mAh Li-ion Battery Pack  
**WEIGHT** 1880g  
**DIMENSION** 215 x 192 x 285 mm



EASY TO REMOVE BATTERY PACK



QUICK RELEASE TRIPOD AVAILABLE

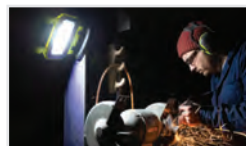

STRONG MAGNETIC FEET



USB POWER BANK FACILITY