



Connect to the future

Service cordons
BP 30 Rue Velpeau
37110 CHATEAU-RENAULT

FICHE TECHNIQUE CORDON

TECHNICAL DATA SHEET CABLE ASSEMBLY

PART NUMBER : R285.425.000

Issue : 00


Date : 01/06/04

Customer : FARNELL UK

Specification : NA

Edition / Issue : - NA Date : NA

All dimensions are in mm

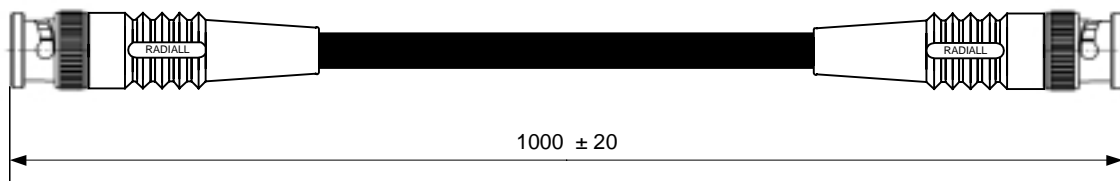

Connectors designation :	Connector 1 : BNC straight plug crimp type (R141.082.161) Torque Wrench : NA	Connector 2 : BNC straight plug crimp type (R141.082.161) Torque Wrench : NA
Cable designation :	KX15 (C291.305.010)	
Cable colour :	Black	
Outer diameter :	4.95mm	
Marking:	NA	

ELECTRICAL CHARACTERISTICS :

High Frequency

Characteristic impedance : **50Ω**

Frequency range : **DC-1GHz**

Insertion Loss : **NA**

Return Loss. : **NA**

Low Frequency

Insulation Resistance : **5000 Mohms mini**

Voltage Rating : **500 Vrms maxi**

CUSTOMER'S APPROVAL

MECHANICAL CHARACTERISTICS :

Static bending radius : **20mm**

Cable crush resistance : **NA**

Life (connectors) : **100 matings**

Service or
Company's stamp

Name
Date

ENVIRONMENTAL CHARACTERISTICS :

Temperature range : **-35°C/+70°C**

J.MOLLES	04/23	01/06/04	Création / First Issue	O. LE FOULER	1/1
Nom / Name	Edition / Issue	Date	Modification	Vérfié par / Checked by	