


VG41DA Video Splitter

KEY FEATURES

 
Video Distribution Amplifier, Send one VGA Source to Multiple Locations
Extend signal up to (65 meters) 213 feet

- 400 MHz pixel frequency
- Easy installation
- Supports DDC, DDC2, DDC2B (for video port 1)
- Can be cascaded
- Output is compatible with standard VGA card
- 1U rack design

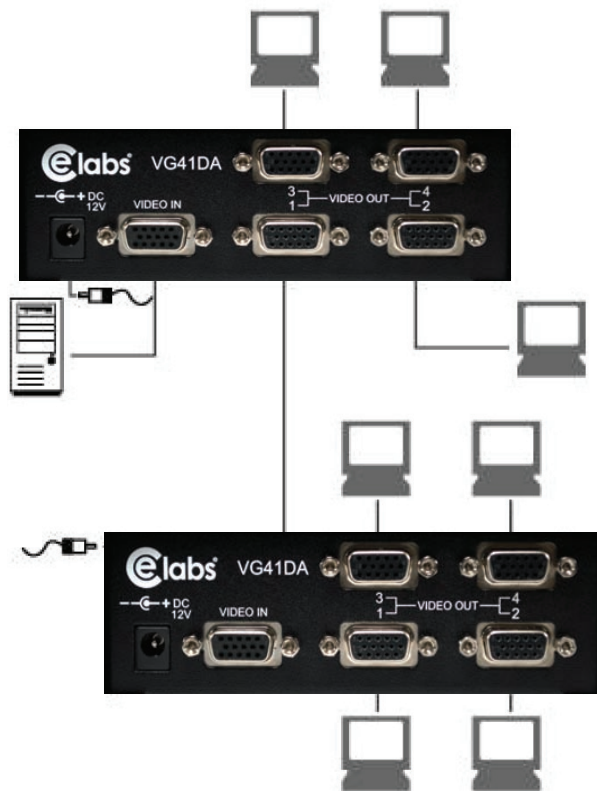

Specifications

Function:

| | |
|---------------------------------------|--|
| Video Input Connector (HD-15 Female): | 1 |
| Video Output Connector (HD-15 Female) | 4 |
| Pixel Frequency: | 400 MHz |
| Max. Resolution: | 2048 x 1536 60 Hz |
| Cable Distance (device to monitor): | 213 feet (65m) |
| Signal Type: | VGA, SVGA, XGA, OXGA, UXGA, Multisync |
| Power Adapter (Min): | DC 12V  2.1mm |
| Housing: | Metal |
| Weight: | 1 lb |
| Dimensions (L x W x H): | 5.1" x 3" x 1.7" |

