


VG41DA Video Splitter

KEY FEATURES

Video Distribution Amplifier, Send one VGA Source to Multiple Locations
Extend signal up to (65 meters) 213 feet

- 400 MHz pixel frequency
- Easy installation
- Supports DDC, DDC2, DDC2B (for video port 1)
- Can be cascaded
- Output is compatible with standard VGA card
- 1U rack design

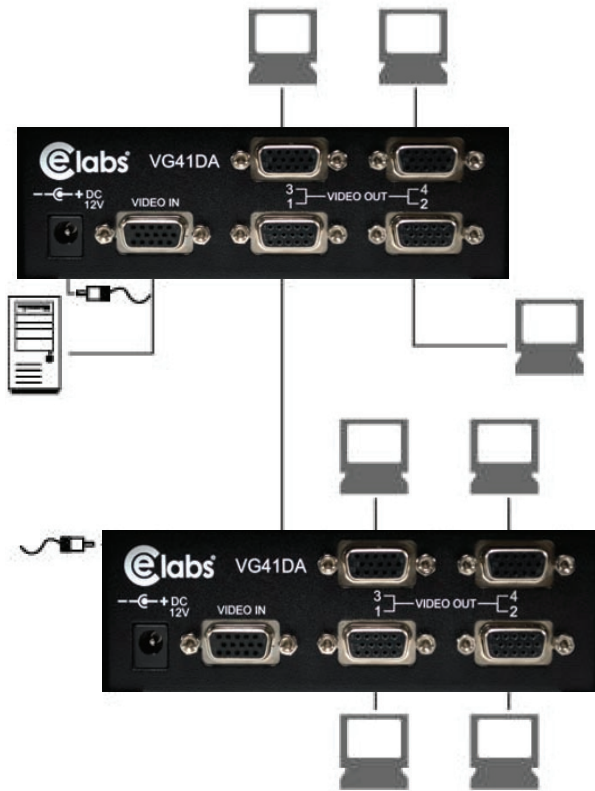

Specifications

Function:

Video Input Connector (HD-15 Female):	1
Video Output Connector (HD-15 Female):	4
Pixel Frequency:	400 MHz
Max. Resolution:	2048 x 1536 60 Hz
Cable Distance (device to monitor):	213 feet (65m)
Signal Type:	VGA, SVGA, XGA, OXGA, UXGA, Multisync
Power Adapter (Min):	DC 12V 2.1mm
Housing:	Metal
Weight:	1 lb
Dimensions (L x W x H):	5.1" x 3" x 1.7"

