


**PARAMETERS**

Impedance	8 Ohm
Re	7.2 ohms
Le	0.71 mH
Fs	100Hz
Qms	4.45
Qes	0.77
Qts	0.65
Mms	6g
Cms	0.24mm/N
Sd	65.04cm <sup>2</sup>
BL	6.81Tm
Vas	1.47liters
Xmas	1mm
VC diameter	1"
SPL	86dB
RMS power	30Watts
Frequency Response	100 to 10,000Hz

**SPL vs Freq**

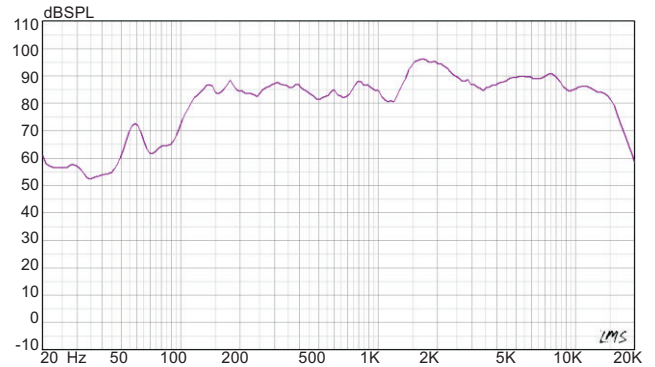

**Impedance vs Freq**

