


**PARAMETERS**

Impedance	8 Ohm
Re	7.6 ohms
Le	1.28 mH
Fs	52.8Hz
Qms	5.47
Qes	0.78
Qts	0.68
Mms	22.57g
Cms	0.4mm/N
Sd	226.9cm <sup>2</sup>
BL	8.54Tm
Vas	29.38 liters
Xmax	3 mm
VC diameter	1.5"
SPL	89.3dB
RMS power	60Watts
Frequency Response	53 to 13,000Hz

**SPL vs Freq**

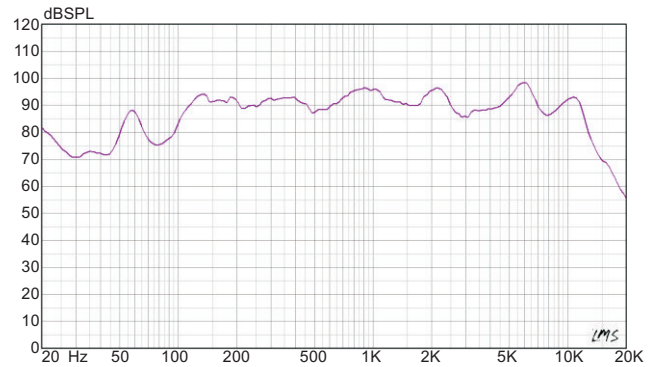

**Impedance vs Freq**

