


PARAMETERS

Impedance	8 Ohm
Re	7.2 ohms
Le	0.85 mH
Fs	90Hz
Qms	3.17
Qes	2.01
Qts	1.23
Mms	7.79g
Cms	0.24mm/N
Sd	76.98cm ²
BL	4.48Tm
Vas	1.98liters
Xmax	2.5mm
VC diameter	1"
SPL	87dB
RMS power	70Watts
Frequency Response	90 to 8,000Hz

SPL vs Freq

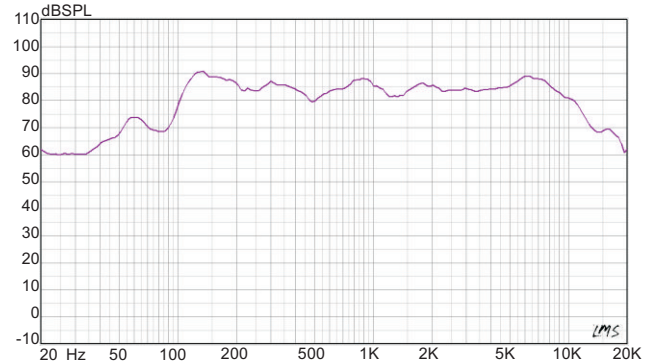

Impedance vs Freq

