



PARAMETERS

Impedance	8 Ohm
Re	7.6 ohms
Le	1.09 mH
Fs	54.7Hz
Qms	3.22
Qes	1.41
Qts	0.98
Mms	31.97g
Cms	0.26mm/N
Sd	226.9cm ²
BL	7.69Tm
Vas	19.35 liters
Xmax	3 mm
VC diameter	1.5"
SPL	85.4dB
RMS power	65Watts
Frequency Response	55 to 3,000Hz

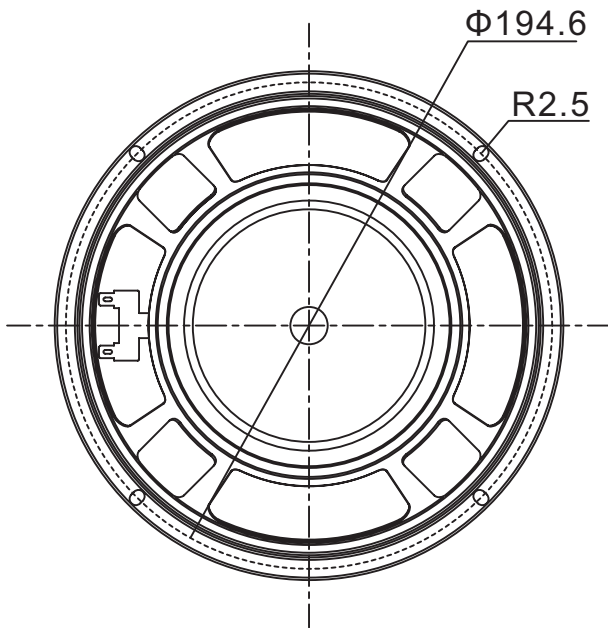

SPL vs Freq

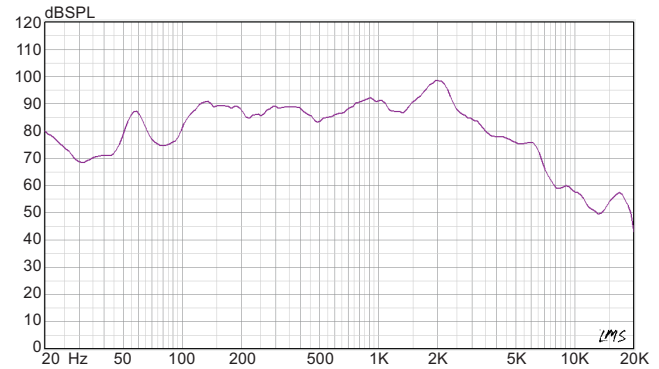

Impedance vs Freq

