

# 4-Port USB Cable KVM Switch

GCS24U



- One USB keyboard, USB mouse, and VGA monitor control four computers
- Max resolution: 2048 x 1536, DDC2B
- Plug-n-Play monitor support
- Molded-in cables to simplify setup
- Compact design features two attached KVM (USB and VGA) cables
- Compatible with PC, MAC and SUN operating platforms
- Supports Windows 2000 or higher, Mac OS 9.0 or higher, Sun Solaris 9 or higher
- No software drivers required – simply connect the cables to the computers
- Computer selection via 6 ft remote control cable that can be placed on your desk for easy reach
- Full Mac keyboard support
- Supports programmable mice
- No power adapter required


IOGEAR's new GCS24U 4-Port USB Cable KVM allows users to share a VGA monitor, a USB mouse, and a USB keyboard between four computers. Users can switch between computers using a manual switch located on a wired remote control that can be placed conveniently on your desk. It offers an out-of-box / entirely plug-in-play solution with no additional cables or software installation needed. It supports multiple operating systems including Windows, Sun, and Mac. It is also powered through the USB bus and thus does not require a power supply to run. It is the ideal KVM for those who want a competitively priced, entry level KVM that will allow them to multitask with four computers at their disposal.



## 4-Port USB Cable KVM Switch

### How does it work?

- Connect your monitor, keyboard and mouse to the KVM
- Connect the KVM USB cables to each computer
- Press the button on the remote controller to switch computers

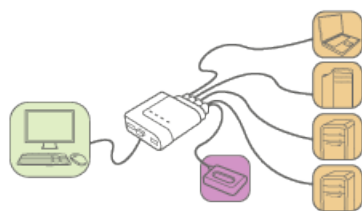

### Requirements:

- Console
  - 1 VGA display
  - 1 set of USB keyboard and mouse

### Computers

- 1 VGA port
- 2 USB ports

### Operating Systems

- Windows XP, Windows Vista (32-bit / 64-bit)
- Mac OS X v10.3.9 or later
- Sun Solaris
- Linux

### Package Contents:

- 1 x 4-Port USB Cable KVM
- 1 x Quick Start Guide
- 1 x Warranty Card

### SPECIFICATIONS

Function	
Housing	
Case	Plastic
Console Connectors	
Monitor	1 x HDB-15 Female
Keyboard	1 x Type-A Female
Mouse	1 x Type-A Female
CPU Connectors	
Monitor	4 x HDB-15 Male
Keyboard & Mouse	4 x Type-A Male
Switches	
Port Selection	Push Button
Video Resolution	2048x1536, DDC2B
Cable Length	4ft
Cable Type	Bonded with KVM
Environment	
Operation Temperature	0C-50C
Storage Temperature	-20C-60C
Humidity	0-80% RH, NC

Dimensions	
POP Information	
10" Peg Hook	3
6" Peg Hook	2
Unit Dimensions	
Width	6.375in.
Height	7.875in.
Depth	2.375in.
Unit Package Dimensions	
Width	6.625in.
Height	9.125in.
Depth	3.875in.
Master Carton	
Width	9.75in.
Height	7.375in.
Depth	16in.
Master Carton Qty.	6
Weight	
Master Carton Wt.	11.22lb
Unit Pack Wt.	1.7lb
Unit Wt.	1.46lb