




- Dry Cell operation
- All ABS Body , sturdy yet lightweight
- Built-in Siren & Microphone
- Clear sound, long range & efficient design
- Conveniently located Volume Control & Switch

Application Examples


SPECIFICATIONS

Power Output : **40 Watts**
Voice Range : **1000 yards**
Power Source : 4xUM-1 Cells
Battery Life : 6-8 hrs.
Microphone : Unidirectional
Dimensions : Diameter 6 1/4" x Length 10"
Weight : 1.15 Lbs

Design & Specifications subject to change without notice.

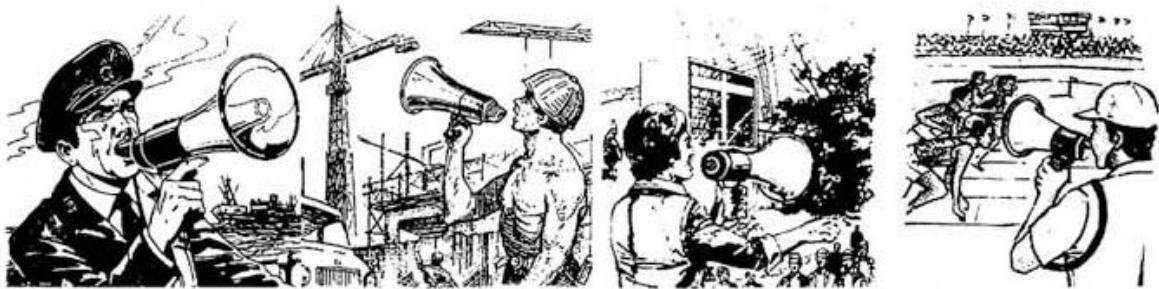

*Ideal for Crowd Control....Fire Fighting....Rescue Operations....Construction Sites....
Sports Events....Electioneering....Field Publicity....Film shooting....*

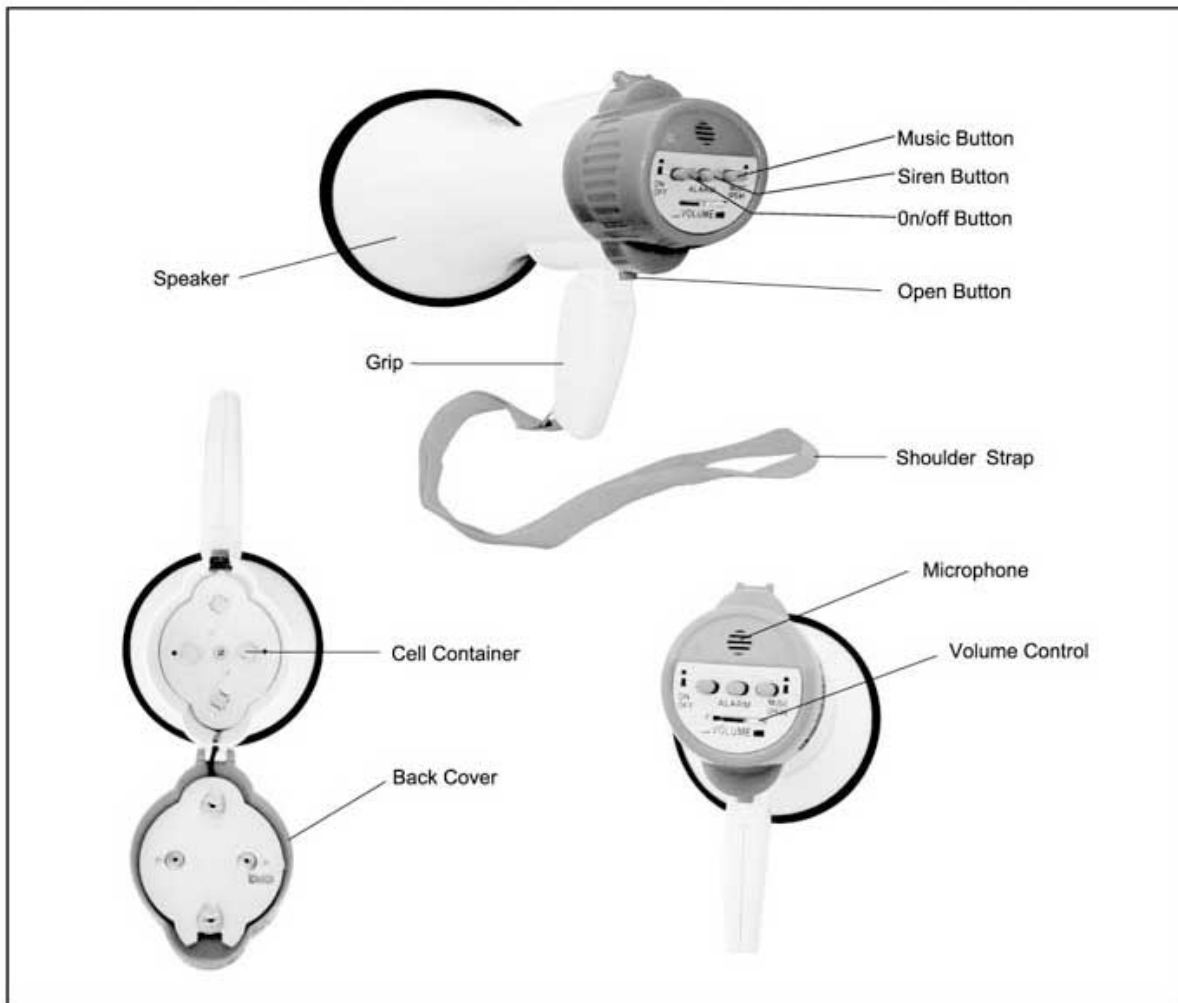

OPERATION

Open the Back Cover by pressing the Open Button.

Insert 4 pcs. UM-1 Cells then close the back cover until it locks. Now your Megaphone is ready for Action!

To activate the megaphone, press the ON/OFF Button on the Back Cover.

When using the megaphone, place your lips as close as possible to the Microphone. Adjust the Volume Control to the desired level without causing any howling or feedback.

Press Music button to activate soft music, or Press Siren button to activate Emergency Siren. To Switch off the Siren, press the same button again, or press the ON/OFF button.

PRECAUTIONS

Ensure correct polarity of Cells.

Please use new batteries/cells always.

When the megaphone is not in use for a long period, remove the dry cells.

Drained cells will not give sufficient sound volume.

Replace cells at regular intervals, for optimum result.