

**Industrial Ethernet
IE-FCM-USB-AB**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com



Service interface FrontCom[®] Micro with USB in IP65

General ordering data

Type	IE-FCM-USB-AB
Order No.	1222550000
Version	FrontCom Micro USB coupling, USB 2.0, Typ A-B
GTIN (EAN)	4050118005806
Qty.	10 pc(s).

Data sheet

**Industrial Ethernet
IE-FCM-USB-AB**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 1429-0
 Fax: +49 5231 14292083
 www.weidmueller.com

Technical data

Dimensions and weights

Wall thickness, max.	3 mm	Wall thickness, min.	1 mm
Net weight	24.08 g		

Temperatures

Operating temperature	-40 °C...70 °C	Storage temperature	
Installation temperature			

General Info

Connection 1	USB A	Connection 2	USB B
Description of article	FrontCom Micro USB coupling, USB 2.0	Wiring	Typ A-B
Colour	Black	Housing main material	PA UL 94 V0
Type of mounting	Cabinet, Distribution box	Shielding	360° shield contact
Protection degree	IP65 in acc. with DIN EN 60529	Plugging cycles	≥ 1500

Standards

Connector standard	IEC 61076-3-107	Certificate no. (cULus)	E316369
--------------------	-----------------	-------------------------	---------

Downloads

UL Approval	DUXR.E316369.pdf
-------------	------------------

Classifications

ETIM 6.0	EC001121	eClass 6.2	27-25-05-04
eClass 7.1	27-25-05-04	eClass 8.1	19-17-01-25
eClass 9.0	19-17-01-25	eClass 9.1	27-18-90-90

Approvals

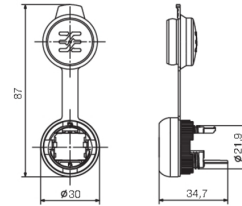
Approvals



ROHS	Conform
------	---------

Data sheet**Industrial Ethernet
IE-FCM-USB-AB**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Drawings**Dimensioned drawing****Installation cut-out**