



Datenblatt - Fiche technique - Data sheet

11.01.6230




ROLINE RS232-Kabel 9pol ST-BU, 3,0m

ROLINE Câble RS-232 9 pôles M/F, 3,0m

ROLINE RS232 Cable, DB9 M - F, 3 m

RoHS COMPLIANT

1800±50/-0MM

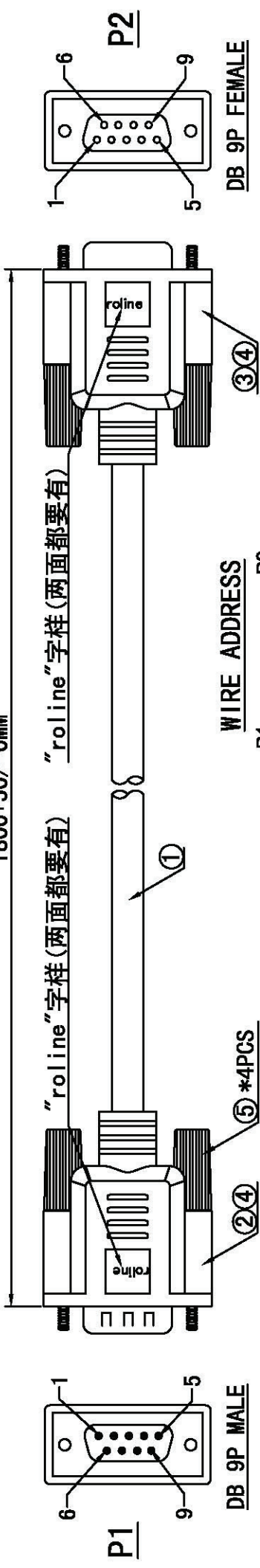


WIRE ADDRESS

- | | |
|-------|-------|
| P1 | P2 |
| 1 | 1 |
| 2 | 2 |
| 3 | 3 |
| 4 | 4 |
| 5 | 5 |
| 6 | 6 |
| 7 | 7 |
| 8 | 8 |
| 9 | 9 |
| SHELL | SHELL |


- NOTE:
1. CABLE: NON-JUL 30AWG*9C+AE OD=5.0MM JACKET: PVC BEIGE;
 2. CONN: DB 9P MALE INSULATION: BLACK, SHELL NICKEL-PLATED;
 3. CONN: DB 9P FEMALE INSULATION: BLACK, SHELL NICKEL-PLATED;
 4. OUTER MOLD: PVC 45P BEIGE;
 5. SCREW: #4-40UNC 2.3*44MM BEIGE.

Electronic Test:


1. 100% TEST OPEN SHORT MIS-WIRE;
2. INSULATION RESISTANCE: 5M OHM MIN;

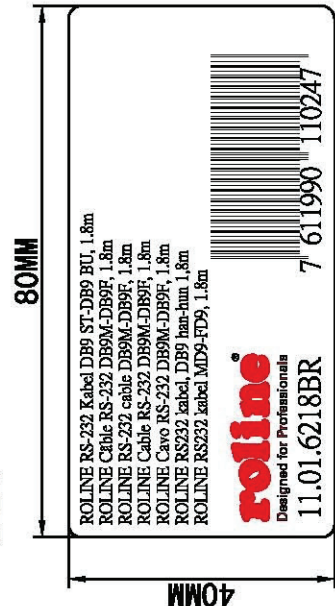


STICKER

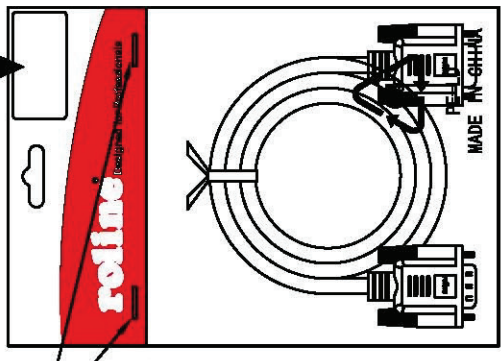

1PCS/PE BAG(200*300*0.06MM) + HEAD
+STICKER + 50PCS/CTN

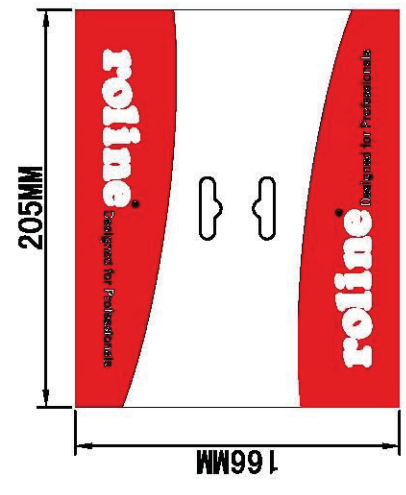

HEAD

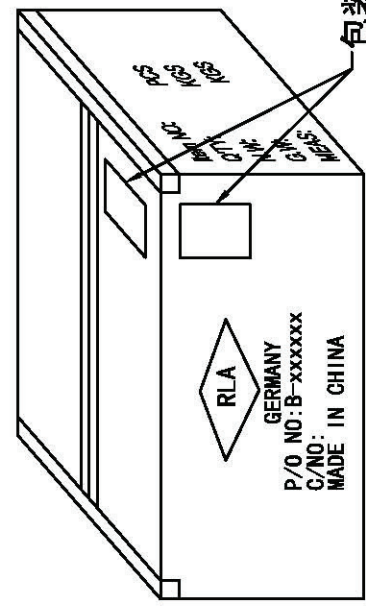

外箱尺寸:
0.6' (42*28*16CM)
50PCS/箱

包装箱贴纸 (客供)
条码朝外

Company	Goods Code	Draw	FC038	Jack	Date	2012-07-14
ITEM NO	11.01.6218	Check			Date	
Goods NO		Approval			Date	
origina1NO.	Unit (MM)			VER. A	REVISE	Date
Rotronic. Co., Ltd						
D						
C						
B						
1PCS/PE BAG(200*300*0.06MM) + HEAD +STICKER + 50PCS/CTN						