


Mounting Brackets

Option 2: Locking

- Locked connections
- Vertical hanging / standing travels
- Extreme accelerations
- Corrosion-resistant
- If the 1st chain link must pivot
- Gliding applications


26...1PZB
Moving end

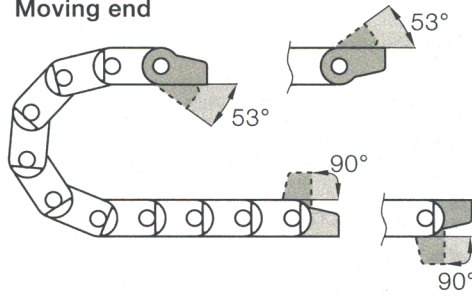

26...2PZB
Fixed end

Option 2: polymer locking

- Locked connection

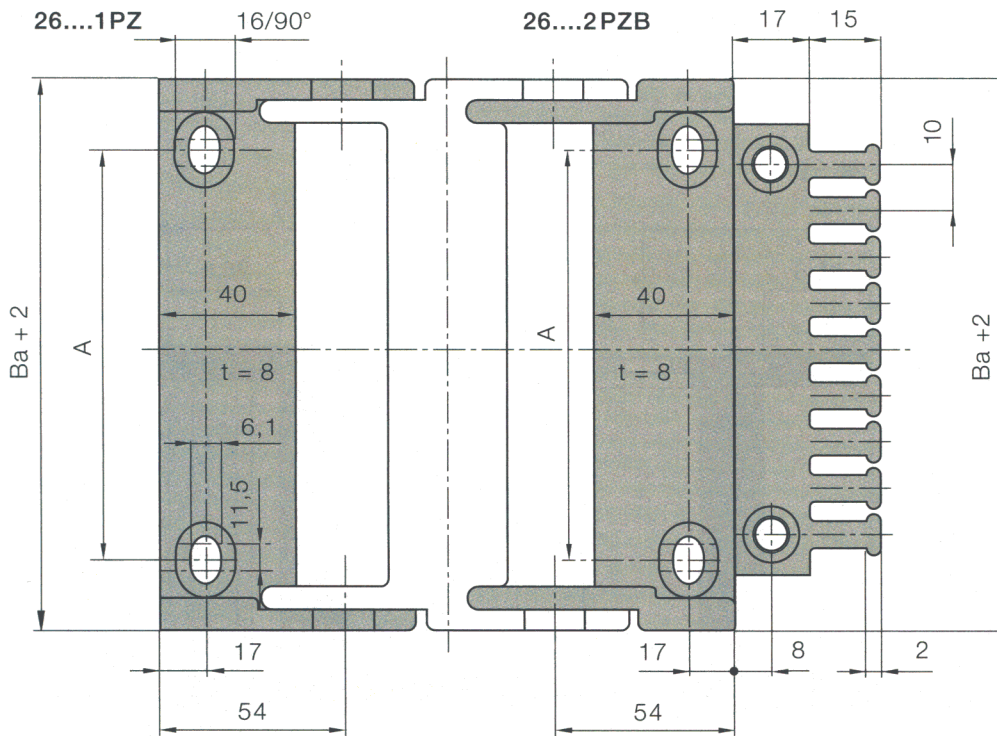

Chain Type	Part No. Full Set with Tiewrap Plates	Part No. with Tiewrap Plates and 10 Cable Tiewraps	Part No. Mounting Bracket Set	Dimension A in mm
26/27/27i.05	2605.12PZB	2605.12PZBK1	2605.12PZ	30
26/27/27i.07	2607.12PZB	2607.12PZBK1	2607.12PZ	55
26/27/27i.10	2610.12PZB	2610.12PZBK1	2610.12PZ	80
26/27/27i.12	2612.12PZB	2612.12PZBK1	2612.12PZ	105
26/27/27i.15	2615.12PZB	2615.12PZBK1	2615.12PZ	130
26/27/27i.17	2617.12PZB	2617.12PZBK1	2617.12PZ	155
26/27/27i.20	2620.12PZB	2620.12PZBK1	2620.12PZ	180

26...12 PZB = Full set, each part with pin/bore, including tiewrap plates

26...1 PZB = Mounting bracket with bore, including tiewrap plates

26...2 PZB = Mounting bracket with pin, including tiewrap plates

Phone +49- (0) 22 03 96 49-0
Fax +49- (0) 22 03 96 49-222

