


# Mounting Brackets

## Option 2: Locking

- Locked connections
- Vertical hanging / standing travels
- Extreme accelerations
- Corrosion-resistant
- If the 1st chain link must pivot
- Gliding applications



2....1PZB  
Moving end

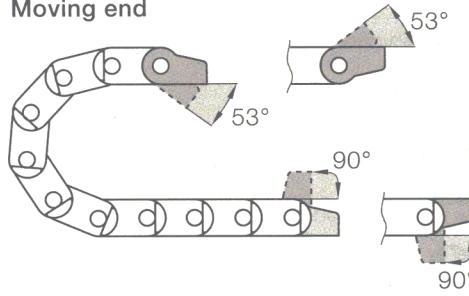

2....2PZB  
Fixed end

## Option 2: polymer locking

- Locked connection

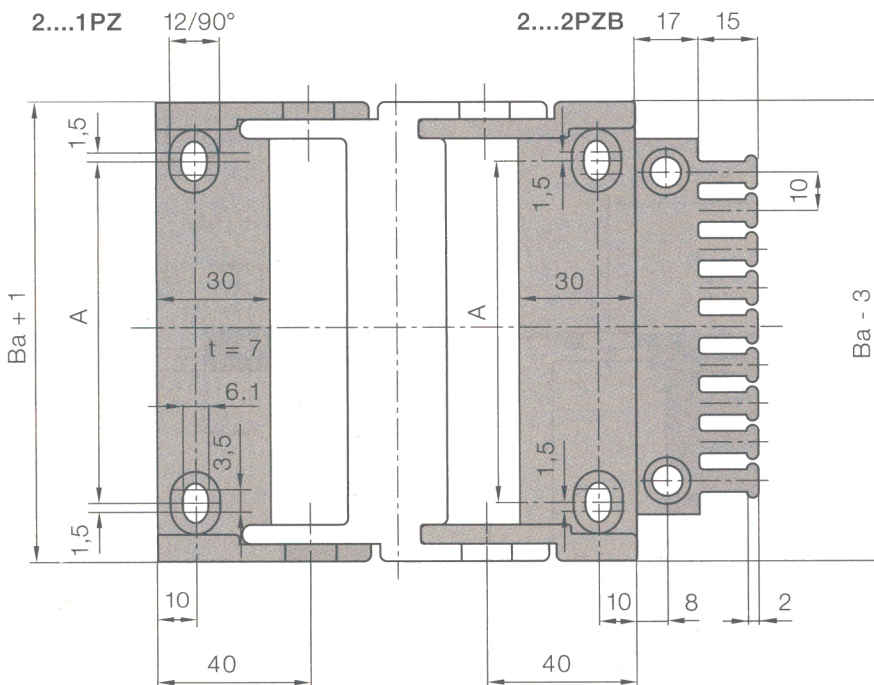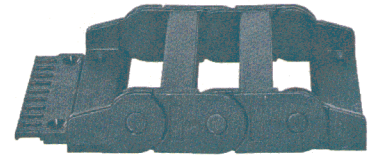

Chain Type	Part No. Full Set with Tiewrap Plates	Part No. with Tiewrap Plates and 10 Cable Tiewraps	Part No. Mounting Bracket Set	Dimension A in mm
200/240/250.02	2020.12PZB	2020.12PZBK1	2020.12PZ	12
200/240/250.03	2030.12PZB	2030.12PZBK1	2030.12PZ	25
200/240/250.05	2050.12PZB	2050.12PZBK1	2050.12PZ	44
200/240/250.07	2070.12PZB	2070.12PZBK1	2070.12PZ	64
200/240/250.09	2090.12PZB	2090.12PZBK1	2090.12PZ	77
200/240/250.10	2100.12PZB	2100.12PZBK1	2100.12PZ	90
200/240/250.12	2125.12PZB	2125.12PZBK1	2125.12PZ	112

- 2...12 PZB = Full set, each part with pin/bore, including tiewrap plates
- 2...1 PZB = Mounting bracket with bore, including tiewrap plates
- 2...2 PZB = Mounting bracket with pin, including tiewrap plates

Phone +49- (0) 22 03 96 49-0  
Fax +49- (0) 22 03 96 49-222

