


# Rotary Burrs



## Tungsten Carbide



- A range of tungsten carbide rotary burrs
- They achieve a high stock removal combined with smooth finish on metal and plastics
- Ideally suited for freehand stock removal, weld preparation and finishing of alloy steel

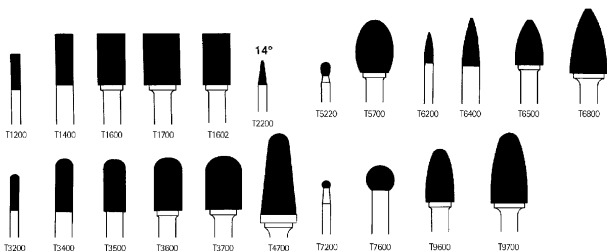

Style	Head ∅	Head Length	Shank ∅	Overall Length	Mftrs List No.	Order Code
Cone	3	11	3	38	T2200	700-9768
Ball nosed cylinder	3	13	3	38	T3200	700-9770
Ball nosed cylinder	6	19	6	50	T3400	700-9781
Ball nosed cylinder	8	19	6	65	T3500	700-9793
Ball nosed cylinder	10	19	6	65	T3600	700-9800
Ball nosed cylinder	13	19	6	65	T3700	700-9811
Ball nosed cone	13	30	6	75	T4700	700-9823
Oval	3	6	3	38	T5220	700-9835
Oval	13	22	6	67	T5700	700-9847
Tree	3	13	3	38	T6200	700-9859
Tree	6	16	6	50	T6400	700-9860
Tree	10	19	6	65	T6500	700-9872
Tree	13	25	6	70	T6800	700-9884
Ball	3	2.7	3	38	T7200	700-9896
Ball	10	9	6	53	T7600	700-9902
Ball nosed tree	10	19	6	65	T9600	700-9914
Ball nosed tree	13	25	6	70	T9700	700-9926
Cylinder	3	13	3	38	T1200	700-9938
Cylinder	6	19	6	50	T1400	700-9940
Cylinder	10	19	6	65	T1600	700-9951
Cylinder	13	19	6	65	T1700	700-9963
Cylinder	10	19	6	65	T1602	700-9975