




## IEC Thermocouple Extension Leads with Miniature or Standard Thermocouple Connectors

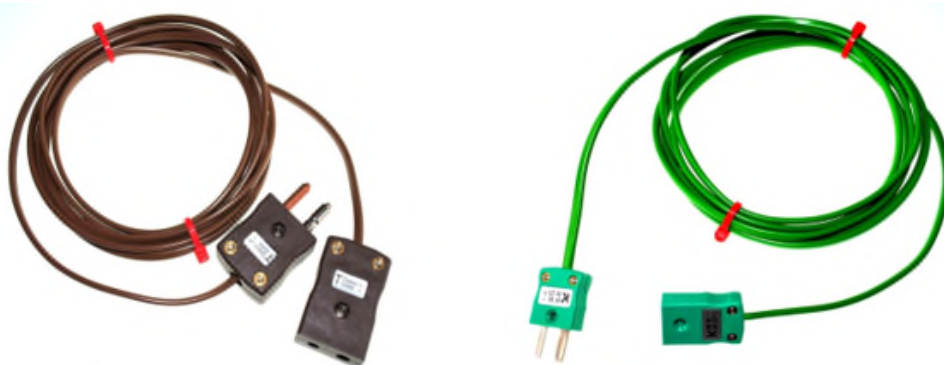

Thermocouple extension leads available with either miniature or standard IEC thermocouple connectors, types K, J or T.

### Thermocouple Cable Construction:

Single pair 7/0.2 PVC insulated cable / wire  
Laid flat, side by side & PVC sheathed  
Tolerance class 2  
Insulation rating -10 to 105°C

### Miniature Thermocouple Connectors:

Miniature connector with flat plug pins  
Miniature socket with thermocouple contacts  
Contacts are polarised to prevent incorrect connection  
Max temperature 220°C

### Standard Thermocouple Connectors:

Standard connector with solid, round plug pins  
Standard socket with thermocouple contacts  
Contacts are polarised to prevent incorrect connection  
Max temperature 220°C

TYPE	CONNECTOR SIZE	CABLE LENGTH	CODE	IEC COLOUR CODE	PART NUMBER
J	Miniature	5	EXT-J-C1-5.0-MP-MS	BLACK	XF-1018-FAR
T	Miniature	2	EXT-T-C1-2.0-MP-MS	BROWN	XF-1019-FAR
T	Miniature	5	EXT-T-C1-5.0-MP-MS	BROWN	XF-1020-FAR
K	Standard	10	EXT-K-C1-10.0-SP-SS	GREEN	XF-1021-FAR

### About Labfacility

Formed in 1971, Labfacility specialize in the field of Temperature and Process Measurement.

We are the largest UK manufacturer of both temperature sensors and thermocouple connectors.

### Quality & Service

Quality and Service are key elements in the continued growth of Labfacility.

Technical support is always freely available from our experienced technical sales teams and the company has ISO9001 accreditation.

### Contact Details

Email  
sales@labfacility.com

Website  
www.labfacility.com