



Quality Products. Service Excellence.

20 Amp Heavy Duty Outlet Strip 1589 Series


Features



- Built to meet the rugged requirements of industrial and commercial use.
- All metal housing – tough extruded aluminum case with black powder-coated steel cover.
- Available with on/off switch or red pilot light to indicate power on.
- Mounting feet (with keyhole slots) allow temporary work station mounting if desired.

Specifications

- Heavy-duty black receptacles rated for 20A, 125VAC service (NEMA 5-20R, Single T-Slot).
- Heavy-duty power cord – 12/3 SJT for extreme temperature ranges.
- Integral molded plug with straight blade (NEMA 5-20P) or locking (NEMA L5-20P) configuration.
- Includes 20A, 125VAC circuit breaker to prevent accidental line overload.
- CSA certified, Standards C22.2 (No. 21-95 and No. 42-99).
- UL/cUL Listed Standard UL1363 file No. E166039 & CSA C22.2 No. 308-14

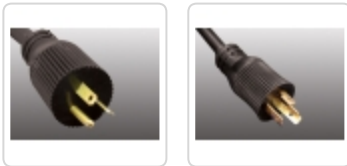

Accessories

- Rack Cabinet Vertical Mount Adaptor



On/Off Switch Part No.	Illuminated Light Only Part No.	Overall Dimensions			Outlet Qty	Outlet NEMA Type	Cord Length (ft)	Plug Type	Plug NEMA Type
		Height	Width	Length					
1589H4C1	1589T4C1	2.33	2.13	10.18	4	5-20R	6	Locking	L5-20P
1589H4D1	1589T4D1	2.33	2.13	10.18	4	5-20R	15	Locking	L5-20P
1589H4F1	1589T4F1	2.33	2.13	10.18	4	5-20R	6	Straight	5-20P
1589H4G1	1589T4G1	2.33	2.13	10.18	4	5-20R	15	Straight	5-20P
1589H6C1	1589T6C1	2.33	2.13	13.36	6	5-20R	6	Locking	L5-20P
1589H6D1	1589T6D1	2.33	2.13	13.36	6	5-20R	15	Locking	L5-20P
1589H6F1	1589T6F1	2.33	2.13	13.36	6	5-20R	6	Straight	5-20P
1589H6G1	1589T6G1	2.33	2.13	13.36	6	5-20R	15	Straight	5-20P
1589H8C1	1589T8C1	2.33	2.13	16.51	8	5-20R	6	Locking	L5-20P
1589H8D1	1589T8D1	2.33	2.13	16.51	8	5-20R	15	Locking	L5-20P
1589H8F1	1589T8F1	2.33	2.13	16.51	8	5-20R	6	Straight	5-20P
1589H8G1	1589T8G1	2.33	2.13	16.51	8	5-20R	15	Straight	5-20P

Data subject to change without notice

