

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0151320402](#)
Status: **Active**
Overview: [Pico-Lock Connector System](#)
Description: Pico-Lock-to-Pico-Lock Off-the-Shelf (OTS) Cable Assembly, 1.50mm Pitch, Single Row, 150.00mm Length, 4 Circuits, Black

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	15132
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Pico-Lock-to-Pico-Lock
Overview	Pico-Lock Connector System
Product Literature Order No	987651-6143
Product Name	Pico-Lock OTS
UPC	191128284936

Physical

Cable Length	150.00mm
Circuits (Loaded)	4
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	2.261/g
Pitch - Mating Interface	1.50mm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.10mm
Wire Size AWG	24
Wire/Cable Type	UL 1061


Electrical

Voltage - Maximum	150V
-------------------	------

Material Info

Reference - Drawing Numbers

Sales Drawing	151320400-000
---------------	---------------

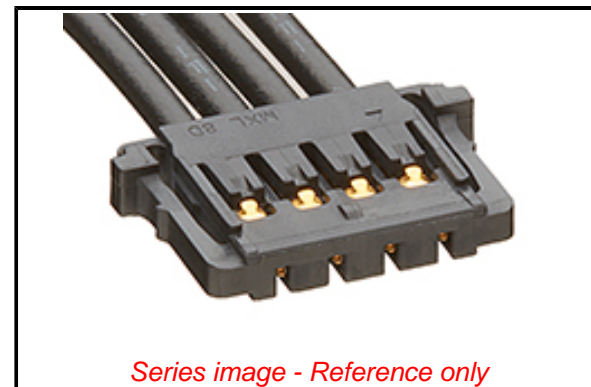

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[15132 Series](#)

Mates With

[504050 Pico-Lock SMT Wire-to-Board Header](#)