

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0151320706](#)
Status: **Active**
Overview: [Pico-Lock Connector System](#)
Description: Pico-Lock-to-Pico-Lock Off-the-Shelf (OTS) Cable Assembly, 1.50mm Pitch, Single Row, 600.00mm Length, 7 Circuits, Black

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Cable Assemblies
 Series [15132](#)
 Assembly Configuration Dual Ended Connectors
 Connector to Connector Pico-Lock-to-Pico-Lock
 Overview [Pico-Lock Connector System](#)
 Product Literature Order No 987651-6143
 Product Name Pico-Lock OTS
 UPC 191128285148

Physical

Cable Length 600.00mm
 Circuits (Loaded) 7
 Color - Resin Black
 Gender Female-Female
 Lock to Mating Part Yes
 Material - Metal Copper Alloy
 Material - Plating Mating Gold
 Material - Plating Termination Tin
 Material - Resin High Temperature Thermoplastic
 Net Weight 14.007/g
 Pitch - Mating Interface 1.50mm
 Single Ended No
 Termination Interface: Style Crimp or Compression
 Wire Insulation Diameter 1.10mm
 Wire Size AWG 24
 Wire/Cable Type UL 1061


Electrical

Voltage - Maximum 150V

Material Info

Reference - Drawing Numbers

Sales Drawing 151320700-000

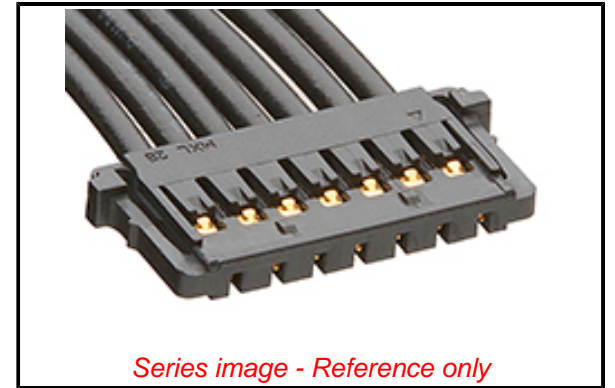

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[15132](#) Series

Mates With

[504050](#) Pico-Lock SMT Wire-to-Board
 Header