

## M12-Round-Plug Connector, Single-Ended Cordsets

 
RKT | RKWT



### 3-, 4-, 5-, and 8-Poles


Actuator/sensor cordset, single-ended, M12, 3-, 4-, 5-, and 8-poles, Female straight connector with self-locking thread and molded cable.

RKT



Actuator/sensor cordset, single-ended, M12, 3-, 4-, 5-, and 8-poles, female 90° connector with self-locking thread and molded cable.


RKWT

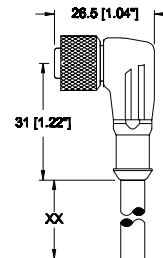


## Pin Assignments

### M12 - Female

 
#### 3 poles




#### 4 poles

 

#### 5 poles

 

#### 8 poles

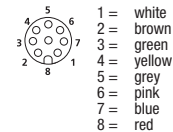

# Be Certain with Belden

## M12-Round-Plug Connector, Single-Ended Cordsets

### Technical Data

#### Environmental

Degree of protection	IP68 / Nema 6P
Operating temperature range	-40°C (-40°F) / +90°C (+194°F)

#### Mechanical

Housing / Molded body	PUR, translucent gray
Insert	PUR, orange
Contact	CuZn, gold-plated
Coupling nut	CuZn, nickel-plated
O-ring	FKM

#### Electrical

Current rating	3-5 poles 4A 8 poles 1.5A
Voltage rating	3-4 poles 250V 5-8 poles 30V

### Cable Specifications

Cable No.	Outer Jacket	Conductor Size	Jacket Color	OD
659	PVC	22 AWG	Gray	.190" (4.82 mm)
646	PVC	22 AWG	Gray	.190" (4.82 mm)
647	PVC	22 AWG	Gray	.212" (5.38 mm)
661	PVC	24 AWG	Gray	.232" (5.89 mm)

Part Number	Pins	Standard Cable Lengths	Characteristics
RKT 4-3-659/...M	3	1M / 2M / 4M / 5M / 6M / 15M / 10M / 20M	
RKT 4-646/...M	4	1M / 2M / 4M / 5M / 6M / 10M / 15M / 20M	
RKT 5-647/...M	5	1M / 2M / 4M / 5M / 6M / 10M / 15M / 20M	
RKT 8-661/...M	8	1M / 2M / 4M / 5M / 6M / 10M / 15M / 20M	
RKWT 4-3-659/...M	3	1M / 2M / 4M / 5M / 6M / 10M / 15M / 20M	
RKWT 4-646/...M	4	1M / 2M / 4M / 5M / 6M / 10M / 15M / 20M	
RKWT 5-647/...M	5	1M / 2M / 4M / 5M / 6M / 10M / 15M / 20M	
RKWT 8-661/...M	8	1M / 2M / 4M / 5M / 6M / 10M / 15M / 20M	