

Digital Depth Gauge


D03198

Digital Depth Gauge

FEATURES

Compact and portable device
High-quality stainless steel measuring bridge
Clear and legible digital LCD display
Highly accurate to 0.03mm

Locks in place with locking screw
Switch between mm and inches quickly
Zero setting at any point in the range

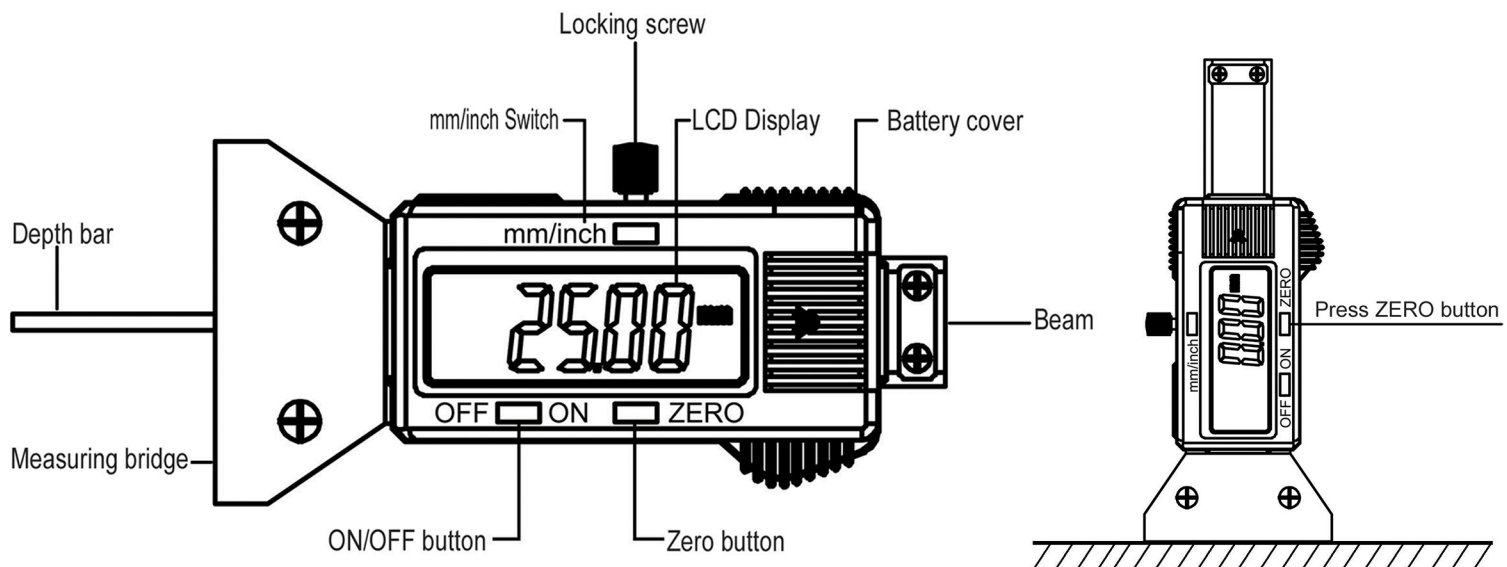

SPECIFICATIONS

1. Range: 0~25.4mm/1"
2. Resolution: 0.01mm/0.0005"
3. Accuracy: $\pm 0.03\text{mm}$
4. Working Temp.: $0^{\circ}\text{C} \sim +40^{\circ}\text{C}$
5. Storage Temp.: $-20^{\circ}\text{C} \sim +70^{\circ}\text{C}$
6. Influence of humidity: $\leq 80\%$

BATTERY REPLACEMENT

