

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300980046](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: MAX-LOC Strain Relief Cord-Sealing Grip, 1/2" NPT, Straight Male, Cable Diameter 4.75-6.35mm (.187-.250")

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159
 UL E76954

General

Product Family Cable Grips
 Series [130098](#)
 Eye Type N/A
 NEMA Rating NEMA 3R
 O-Ring No
 Overview [Strain-Relief Cord Grips](#)
 Product Literature Order No 987651-6081
 Product Name MAX-LOC
 Type Strain Relief Grip
 UPC 78678872116
 Use With 1/2" NPT MAX-LOC Lock Nut [130099-0143](#) , MAX-LOC O-Ring, 1/2" NPT [130180-0314](#) , 1/2" NPT MAX-LOC Gasket [130099-0149](#)
 Woodhead Yes

Physical


Approximate Break Strength N/A
 Bale Length N/A
 Body Style Straight
 Cable Diameter 4.75-6.35mm (.187-.250")
 Color - Grommet Orange
 Gender Male
 Material - Body Nylon
 Material - Grip N/A
 Mesh Length N/A
 Net Weight 30.390/g
 Number of Holes 1
 Thread Size 1/2" NPT

Material Info

Engineering Number 5522

Reference - Drawing Numbers

Sales Drawing SD-130098-003

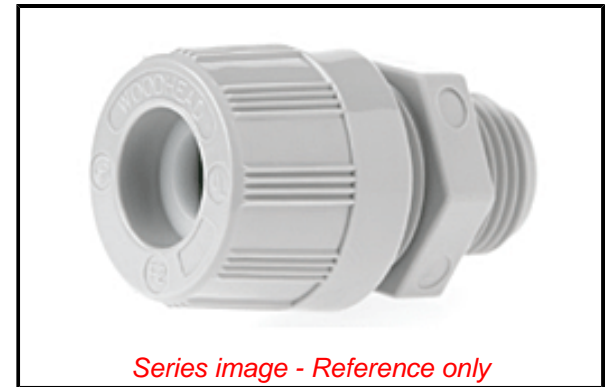

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Not Reviewed
 ELV Not Reviewed
 RoHS Phthalates Not Reviewed

Search Parts in this Series
[130098](#) Series