


# UV Heat Stabilized Cable Ties **pro-POWER**



## Specifications

Material : Nylon 6/6 Polyamide  
 Colour : Black  
 Flammability Rating : UL94V-2

## Diagram

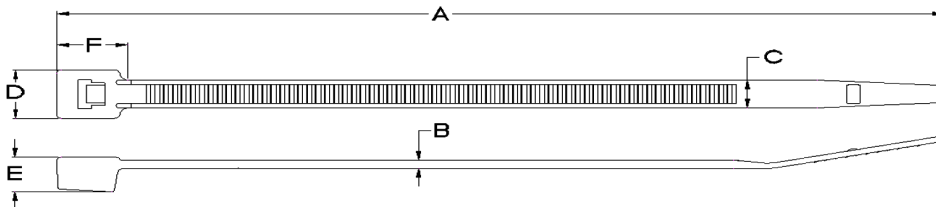

Part Number	Bundle Diameter		A Inches (mm) ±0.125 (3.175)	B Inches (mm) ±0.005 (0.127)	C Inches (mm) ±0.005 (0.127)	D Inches (mm) ±0.02 (0.508)	E Inches (mm) ±0.02 (0.508)	F Inches (mm) ±0.03 (0.762)	Min. Loop Tensile LBs (n)
	Min. Inches (mm)	Max. Inches (mm)							
MC001979	0.062	0.874	4.125	0.042	0.095	0.18	0.15	0.22	18
MC001978	(1.57)	(22.2)	(104.775)	(1.066)	(2.413)	(4.572)	(3.81)	(5.588)	(80)
MC001985	0.062	1.437	5.84	0.049	0.14	0.24	0.175	0.25	40
MC001986	(1.57)	(36.423)	(148.336)	(1.244)	(3.556)	(6.096)	(4.445)	(6.35)	(178)
MC001974	0.062	1.5	6.187	0.042	0.095	0.18	0.15	0.22	18
MC001975	(1.57)	(38.1)	(157.149)	(1.066)	(2.413)	(4.572)	(3.81)	(5.588)	(80)
MC001997	0.062	1.875	7.562	0.052	0.18	0.3 (7.62)	0.215	0.305	50
MC001976	(1.57)	(47.625)	(192.075)	(1.32)	(4.572)	(4.572)	(5.461)	(7.747)	(222)
MC001976	0.062	2.187	8.187	0.042	0.095	0.18	0.15	0.22	18
MC001977	(1.57)	(55.5)	(207.949)	(1.066)	(2.413)	(4.572)	(3.81)	(5.588)	(80)
MC001989	0.062	2.375	8.875	0.049	0.14	0.24	0.175	0.25	40
MC001990	(1.57)	(60.325)	(225.425)	(1.244)	(3.556)	(6.096)	(4.445)	(6.35)	(178)
MC001987	0.062	3.375	10.968	0.054	0.14	0.24	0.175	0.25	40
MC002002	(1.57)	(85.725)	(278.587)	(1.371)	(3.556)	(6.096)	(4.445)	(6.35)	(178)
MC001991	0.062	3.062	11.25	0.052	0.18	0.3 (7.62)	0.215	0.305	50
MC001992	(1.57)	(77.775)	(285.751)	(1.32)	(4.572)	(4.572)	(5.461)	(7.747)	(222)
MC002003	0.062	4	14.25	0.054	0.14	0.24	0.175	0.25	50
MC001995	(1.57)	(101.6)	(361.95)	(1.371)	(3.556)	(6.096)	(4.445)	(6.35)	(222)

# UV Heat Stabilized Cable Ties **pro-POWER**

**Part Number Table**

Description	Colour	Quantity	Part Number
Speciality Cable Tie - UV Heat Stabilized	Black	Pack of 1000	MC001979
		Pack of 100	MC001978
		Pack of 100	MC001985
		Pack of 1000	MC001986
		Pack of 100	MC001974
		Pack of 1000	MC001975
		Pack of 1000	MC001997
		Pack of 100	MC001976
		Pack of 1000	MC001977
		Pack of 100	MC001989
		Pack of 1000	MC001990
		Pack of 100	MC001987
		Pack of 1000	MC002002
		Pack of 100	MC001991
		Pack of 1000	MC001992
		Pack of 100	MC002003
Pack of 500	MC001995		

**Important Notice :** This data sheet and its contents (the "Information") belong to the members of the Premier Farnell group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. pro-POWER is the registered trademark of the Group. © Premier Farnell Limited 2016.