


| MPN | Description |
|-------|------------------------------------|
| RJC08 | RJ45 to Croc Clip Breakout Adapter |

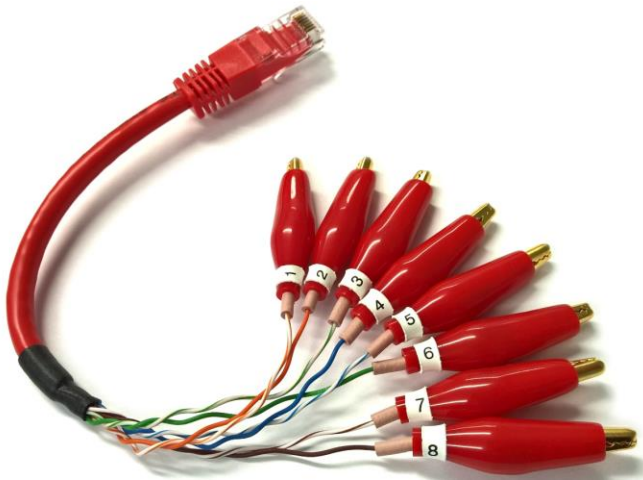

A useful adapter that enables testing and analysis of network cables that have not been terminated with a plug or socket. Also useful for testing and prototyping non-standard connection configurations. Supplied with gold plated crocodile clips and high quality strain relief on all joints. Cable is stranded for extra flexibility.

Individual lines are colour coded and clearly numbered on the croc-clip sleeves.

Overall length (tip to tip) is approximately 220mm (8.7")

Specification Summary

Overall length (tip to tip) is approximately 220mm (8.7")

Surface finish: Gold plating

Cable type: Stranded (not solid core)

Shielding: None

Cable identification: Colour coded and numbered (to international standard TIA/EIA-568-B.1-2001)

| | |
|---|---|
| Dimensions per product | Overall length (tip to tip) is approximately 220mm (8.7") |
| Dimensions per product (packaged) | 150mm x 100mm x 37mm (5.9" x 4" x 1.5") |
| Weight per product (nett) | 0.083kg (3oz) |
| Weight per product (packaged inc docs) | 0.083kg (3oz) |
| Fundamental Materials | Plastic and metal. |
| Certification | CE, WEEE, ROHS |