


12 40 200

Self-Adjusting Insulation Stripper



- For single, multiple and fine stranded conductors with plastic or rubber insulation
- Adapts automatically to the respective cable cross-section; prevents damage to the conductor
- Cutting depth can be adjusted for different insulation materials
- With wire cutter for copper and aluminium wires, multiple stranded up to 10 mm² and single stranded up to 6 mm²
- Smoothly operating mechanism
- Stripping blades and clamping jaws easily replaceable
- Low weight
- Body: plastic, fibreglass-reinforced
- Blade: special tool steel, oil-hardened
- For thin ribbon cables up to 10.0 mm width in a single pass

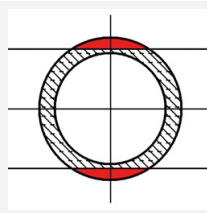


Mode of operation of straight cutters

An incision is made in the red area only.

Not suitable for highly-flexible or armoured insulation materials or for multi-layered insulation.


| | |
|--|---------------|
| Article No. | 12 40 200 |
| EAN | 4003773026662 |
| Stripping capacities in square millimetres mm² | 0,03 - 10,0 |
| Length stop mm | 3,0 - 18,0 |
| Nominal size | 200 mm |
| AWG | 32 - 7 |
| Length mm | 200 |
| Net weight g | 202 |

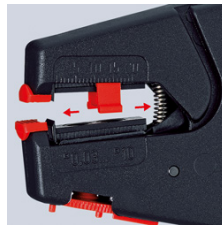

12 40 200: Adjustable length stop



Wire cutter for multiple stranded wire cables up to 10.0 mm²

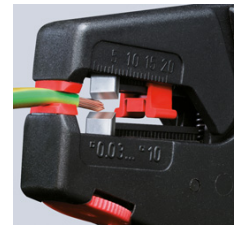

12 40 200: Precise stripping prevents damage to the conductor

technical change and errors excepted



Spare Parts

| Article No. | EAN | |
|-------------|---------------|---|
| 12 49 01 | 4003773026679 | 1 pair of spare blades for 12 40 200 |
| 12 49 02 | 4003773026686 | 1 pair of spare clamping jaws for 12 40 200 |
| 12 49 03 | 4003773026693 | Spare length stop for 12 40 200 |
| 12 49 04 | 4003773053071 | Torsion spring for 12 40/50 200 |
| 12 49 05 | 4003773053088 | Coil spring in the head for 12 40/50 200 |