

95 61 190

Wire Rope Cutter forged



- With two crimping dies for end caps on Bowden cable sheaths and end ferrules for traction cables
- Comfortable work thanks to handy, slim design and internal opening spring
- Bolted joint for precise blade guidance, re-adjustable
- High leverage for reduced effort
- Cutting-edge hardness approx. 64 HRC
- Chrome vanadium heavy-duty steel, forged, multi stage oil-hardened

Cuts all wire ropes without splaying, including those that are extremely strong


| | |
|--|----------------|
| Article No. | 95 61 190 |
| EAN | 4003773040651 |
| Head | polished |
| Handles | plastic coated |
| Cutting capacity copper cable, multiple-stranded mm ² | 10,0 |
| Cutting capacity copper cable, fine-stranded (diameter) Ø mm | 6,00 |
| Cutting capacities wire rope (diameter) Ø mm | 5,0 |
| Cutting capacities iron (diameter) Ø mm | 4 |
| Cutting capacities medium hard wire (diameter) Ø mm | 4,0 |
| Cutting capacity copper cable, multiple-stranded (diameter) Ø mm | 7,0 |
| Cutting capacities piano wire (diameter) Ø mm | 2,5 |
| AWG | 7 |
| Length mm | 190 |
| Net weight g | 314 |



Crimping of the end ferrule onto the traction cable



Crimping of the end caps on the Bowden cable sheath

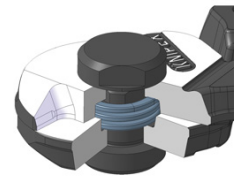

Internal opening spring

technical change and errors excepted

