

ToLEDo GLS

ToLEDo GLS V3 810LM 827 B22 SL

0026675



Product features

-



PRODUCT OVERVIEW

Lamp finish	Frosted
Lamp shape	GLS
Colour temperature (K)	2700
CRI (Ra)	80
Dimmable	No
EAN code	5410288266756
Energy class	A+
Equivalent watt (W)	60
Cap/Base	B22
Type	ToLEDo GLS
Watt (Nominal) (W)	10
Light colour	Homelight
Ordering number	0026675
Efficacy (Rated) (lm/w)	81
Average life (h) - L70/B50	15000
Luminous flux (Rated) (lm)	810
Technology	LED
Voltage (V)	220-240
Colour consistency (SDCM)	6

DATA TABLE

General data

Average life (h) at Ta 25° C	15000
Control gear required	No
Lamp finish	Frosted
Lamp shape	GLS
Dimmable	No
Dry applications use only	Yes

ToLEDo GLS

ToLEDo GLS V3 810LM 827 B22 SL

0026675

EAN code	5410288266756
Energy class	A+
Energy saving lamp	Yes
General application	Hospitality; Residential & Consumer
Intended purpose	No
Cap/Base	B22
Lamp mercury content (mg)	0
Type	ToLEDo GLS
No. of switching cycles before premature failure (min)	50000
Optimal operating condition (°C)	25
Ordering number	0026675
Product name	ToLEDo GLS V3 810LM 827 B22 SL
Average life (h) - L70/B50	15000
Special purpose lamp	No
Starting time (max) (s)	0.05
Technology	LED
Transformer required	No
Warm-up time to 60% of full light (max) (s)	< 1s => 60%
E-number SE	8296523

Optical data

Colour temperature (K)	2700
CRI (Ra)	80
Light colour	Homelight
Lumen maintenance at end of nominal life (%)	70
Luminous flux (Nominal) (lm)	810
Luminous flux (Rated) (lm)	810
Suitable for accent lighting	No
Adjustable chromaticity	No
Colour consistency (SDCM)	6

Electrical data

Current (A)	42
Drive current (mA)	79
Equivalent watt (W)	60
kWh per 1000 hours burning time	10
Lamp power factor	0.5
Watt (Nominal) (W)	10
Efficacy (Rated) (lm/w)	81
Watt (Rated) (W)	10
Voltage (V)	220-240

ToLEDo GLS



ToLEDo GLS V3 810LM 827 B22 SL

0026675

Physical data

Max. Lamp Diameter (mm) - D	60
Lamp Length (mm) - C/L	107
Lamp dimension equal to filament lamp equivalent	Yes

TECHNICAL DRAWINGS

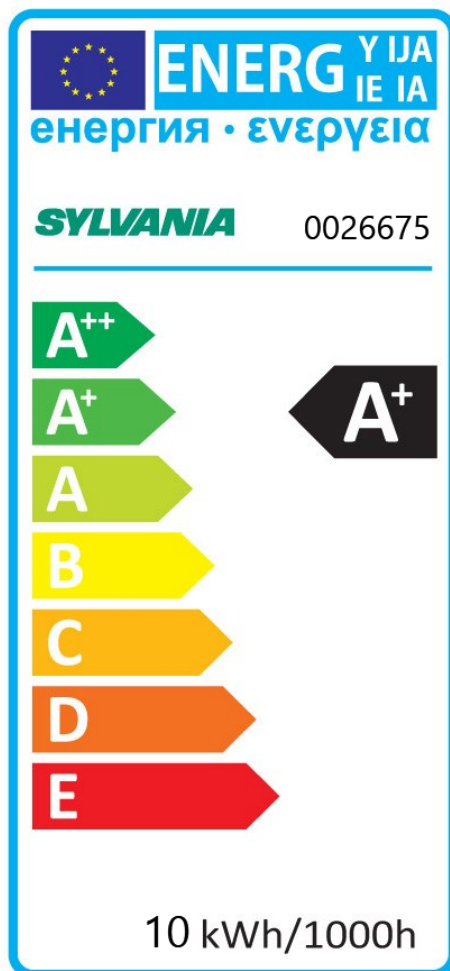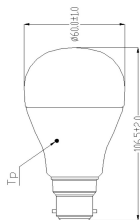

ToLEDo GLS

ToLEDo GLS V3 810LM 827 B22 SL

0026675
