

# PRODUCT SPECIFICATION

<b>Brand</b>	C.K
<b>Product Range</b>	Mighty Rods Cable Rod Set
<b>Catalogue number</b>	5410, 5411, 5420, 5421, 5422, 5430, 5431, 5432, 5433, 5440, 5441
<b>Date</b>	08/02/2018

## Range Description

### MightyRod 10m Cable Rod Set

#### Features

- Triple bonded steel connectors for extreme torsion and tensile strength – threaded, crimped & glued
- High sheen fibreglass composite rods minimise snagging & splintering.
- 5mm rods offer the optimal balance of rigidity & flexibility for the majority of cable routing requirements.
- Slimline connectors reduce snagging and provide accessibility through smaller holes.
- Accessories - Cable hook, Mini eye & ring, Coiled steel flexi lead 190mm, 5mm adaptor (enables interchangeability with other leading cable rod brands).

### MightyRod 3m Cable Rod Set

#### Features:

- Triple bonded steel connectors for extreme torsion and tensile strength – glued, indented and crimped
- High sheen fibreglass composite rods minimise snagging & splintering.
- 5mm rods offer the optimal balance of rigidity & flexibility for the majority of cable routing requirements.
- Slimline connectors reduce snagging and provide accessibility through smaller holes.
- Conveniently sized set for storage in toolbox or tool bag.
- Accessories: cable hook, 190 mm coiled steel flexi lead, mini eye & ring, 5mm adapter.



5410



T5411

### MightyRod PRO Cable Rod Starter Set 5m

#### Features:

- Triple bonded steel connectors for extreme torsion and tensile strength – glued, indented and crimped
- 5 meters of 100% splinter-proof rods
- 2 rod flexibilities for overhead, under floor, tight angled and obstructed runs
- Super tough 'MIGHTY-FIX' zinc plated steel connectors – tensile strength in excess of 275kg
- Accessories: flexi lead (mini-flex), ring, hook

### MightyRod PRO Cable Rod Standard Set 10m

#### Features:

- Triple bonded steel connectors for extreme torsion and tensile strength – glued, indented and crimped
- 10 meters of 100% splinter-proof rods
- 4 rod flexibilities for overhead, under floor, tight angled and obstructed runs
- Super tough 'MIGHTY-FIX' zinc plated steel connectors – tensile strength in excess of 275kg
- Super flexible, low friction, Spira-FLEX rod for tight angled access points
- Accessories: flexi lead (mini-flex), ring, hook, gender changer, flat bullet, domed bullet, in-line swivel

### MightyRod PRO Cable Rod Super Set 12m

#### Features:

- Triple bonded steel connectors for extreme torsion and tensile strength – glued, indented and crimped
- 12 meters of 100% splinter-proof rods
- 4 rod flexibilities for overhead, under floor, tight angled and obstructed runs
- Super flexible, low friction, Spira-FLEX rod for tight angled access points
- Glow in the dark phosphorescent GLO rod for guiding a run of rods in low light conditions
- Super tough 'MIGHTY-FIX' zinc plated steel connectors – tensile strength in excess of 275kg
- Accessories: flexi-lead (mini-flex), ring, hook, gender changer, flat bullet, domed bullet, in-line swivel, torch, magnet, chain



T5420



T5421



T5422

### MightyRod PRO Cable Rod 6mm Pk2

#### Features:

- A pair of flexible 6mmØ rods
- splinterSHIELD – 100% splinter proof shield
- Super tough 'MIGHTY-FIX' zinc plated steel connectors – tensile strength in excess of 275kg

### MightyRod PRO Cable Rod 7mm Pk2

#### Features:

- A pair of flexible 7mmØ rods
- splinterSHIELD – 100% splinter proof shield
- Super tough 'MIGHTY-FIX' zinc plated steel connectors – tensile strength in excess of 275kg

### MightyRod PRO GLO Cable Rod 6mm Pk1

#### Features:

- A flexible 6mmØ phosphorescent GLO rod
- splinterSHIELD – 100% splinter proof shield
- Super tough 'MIGHTY-FIX' zinc plated steel connectors – tensile strength in excess of 275kg

### MightyRod PRO SpiraFlex Cable Rod 4mm Pk1

#### Features:

- A super flexible 4mmØ rod
- Spira-FLEX – super flexible, low friction, Spira-FLEX rod for tight-angled access points
- Helical profile – reduced rod to surface contact to further minimize friction

### MightyRod PRO 7pc Standard Kit Accessory Pack

#### Features:

- Flexi lead, hook, ring, gender changer, flat bullet, domed bullet, in-line swivel



T5430



T5431



T5432



T5433



T5440

### MightyRod PRO 3pc Super Kit Accessory Pack

#### Features:

 
- Torch, magnet, chain

### MightyRod Carry Case

- Durable polyester construction with reinforced base
- Adjustable shoulder strap for convenient carrying
- Two external pockets
  - Large pocket – capable of accommodating C.K MightyRods Toolbox cable rod set
  - Small pocket – to accommodate cable rod accessories

### MightyRod Cable Sock


- Tapered woven steel mesh cable sock that provides a quick and secure method for securing cables to rods



T5411



T5450

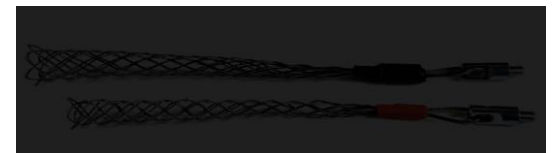

T5442

Item Number	Item Description	EAN No	Commodity code	Carton Qty
T5410	C.K Mighty Rod 10m Cable Rod Set	5013969950304	82055980	3
T5411	MightyRod Tool Box Cable Rod Set 3.3m	5013969950311	82055980	1
T5420	MightyRod PRO Cable Rod Starter Set 5m	5013969950632	82055980	1
T5421	MightyRod PRO Cable Rod Standard Set 10m	5013969950649	82055980	1
T5422	MightyRod PRO Cable Rod Super Set 12m	5013969950656	82055980	1
T5430	MightyRod PRO Cable Rods 6mm Pk2	5013969950663	82055980	1
T5431	MightyRod PRO Cable Rods 7mm Pk2	5013969950670	82055980	1
T5432	MightyRod PRO GLO Cable Rod 6mm Pk1	5013969950687	82055980	1
T5433	MightyRod PRO SpiraFLEX Cable Rod 4mm Pk1	5013969950694	82055980	1
T5440	MightyRod 7pc Standard Kit Accessory Pack	5013969950700	82055980	1
T5441	MightyRod 3pc Super Kit Accessory	5013969950717	82055980	1

	Pack			
T5450	MightyRod Carry Case	5013969244410	4202929810	20
T5442 06	MightyRod Cable Sock 6-10mm	5013969244496	8205598000	500
T5442 11	MightyRod Cable Sock 11-15mm	5013969244502	8205598000	500

Technical product information	
Standards compliance	None applicable
User health and safety information	None applicable
RoHS/WEEE compliance	This product range does not fall within the scope of RoHS or WEEE regulations
Material safety data	None applicable
Warranty	C.K Cable rods are guaranteed for life against imperfect materials or workmanship Normal wear and tear or damage caused through inappropriate use is not covered
Country of origin	Taiwan China – Carry Case

## Dimensional details

Item	Product only				Product on primary packaging			
	Width mm	Depth mm	Height mm	Net weight g	Width mm	Depth mm	Height mm	Gross weight g
T5410	30	30	1125	725	30	30	1125	725
T5411	35	35	460	330	35	35	460	330
T5420	45	45	1300	700	45	45	1300	700
T5421	45	45	1300	935	45	45	1300	935
T5422	45	45	1300	1086	45	45	1300	1086
T5430	60	60	1000	102	60	60	1125	123
T5431	70	70	1000	136	70	70	1125	157
T5432	60	60	1000	51	60	60	1125	72
T5433	40	40	1000	20	40	40	1125	41
T5440	80	230	40	53	80	230	40	85
T5441	70	130	25	41	70	130	25	57
T5450					125	60	530	480
T5442 06	10	200	10	20	60	300	10	26
T5442 11	15	200	15	25	60	300	15	31

Item	Shelf box (secondary packaging)				Euro Pallet data Wi x Hi	
	Width mm	Depth mm	Height mm	Gross weight g	No of cartons on base	Number of rows high
T5410	-	-	-	-		
T5411	-	-	-	-		
T5420	250	180	1310	14640		
T5421	250	180	1310	19280		
T5422	250	180	1310	22360		
T5430	310	90	1160	6430		
T5431	310	90	1160	8130		
T5432	310	90	1160	3880		
T5433	310	90	1160	2330		
T5440	410	930	180	8885		
T5441	240	470	180	6085		
T5450	490	350	570	10000		
T5442 06	310	450	200	13300		
T5442 11	260	520	280	15850		

### Packaging waste details

Item	Primary Packaging				Secondary packaging			
	Plastic g	Use	Card g	Use	Plastic g	Use	Card g	Use
T5410								
T5411								
T5420							500	Box
T5421							500	Box
T5422							500	Box
T5430	10	Bag	11	Card			250	Box
T5431	10	Bag	11	Card			250	Box
T5432	10	Bag	11	Card			250	Box
T5433	10	Bag	11	Card			250	Box
T5440	23	Blister	9	Card			350	Box
T5441	11	Blister	5	Card			350	Box
T5450	3	Bag	15	Card			400	Box
T5442 06	2	Bag	4	Card			350	Box
T5442 11	2	Bag	4	Card			350	Box