


Product data sheet

Characteristics

9050AO10EV02

Pneumatic Timer - on delay - 0.1-60 seconds -
120VAC - SPDT

Product availability : Non-Stock - Not normally stocked in distribution facility

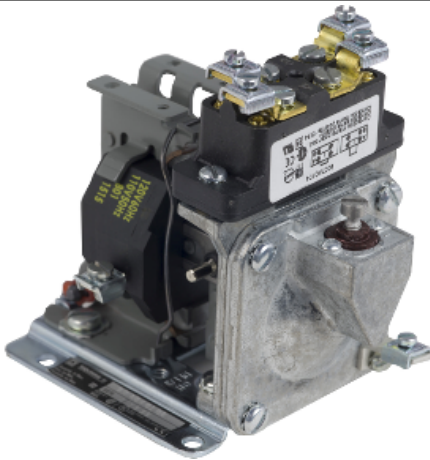

Main

| | |
|------------------------------|----------------------------------|
| Range of product | 9050A/H |
| Product or component type | Timer |
| Time delay type | On-delay |
| Time delay range | 0.1 s...1 min |
| Switch function | SPDT |
| [Uc] control circuit voltage | 110 V AC 50 Hz 120 V AC 60 Hz |
| Contact operation | Time delayed 1 NO + 1 NC |
| Line Rated Current | 15 A |

Complementary

| | |
|---------------------------|---------------------------------------|
| Maximum switching voltage | 600 V AC |
| Electrical connection | Screw-clamp terminals |
| Reset response time | 29 ms - on-delay 27 ms - off-delay |
| Mounting support | Panel |

Environment

| | |
|---------------------------------------|------------------|
| Ambient air temperature for operation | 68...104 °F |
| Product certifications | CSA UL listed |
| Height | 2.64 in (67 mm) |
| Width | 4.02 in (102 mm) |
| Depth | 4.37 in (111 mm) |

Ordering and shipping details

| | |
|-----------------------|---|
| Category | 21631 - 9050 A ONE MINUTE PNEUMATIC TIMER |
| Discount Schedule | CP1 |
| GTIN | 00785901864318 |
| Nbr. of units in pkg. | 1 |
| Package weight(Lbs) | 1.74 |
| Returnability | N |
| Country of origin | MX |

Offer Sustainability

| | |
|------------------------|---|
| RoHS (date code: YYWW) | Compliant - since 1444 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity |
|------------------------|---|

Contractual warranty

| | |
|-----------------|-----------|
| Warranty period | 18 months |
|-----------------|-----------|