


PVC INSULATED FEMALE DISCONNECTS

Specifications

- **Maximum Electrical Rating:** 300 Volts
- **Maximum Temperature:** +75°C
- **Terminal Material:** Brass
- **Plating:** Electro Tin Plated
- **Insulated Material:** Vinyl (PVC)

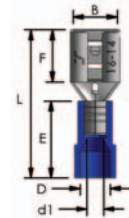


Ordering Information:

| Wire Range AWG / mm ² | NTE Part Number | Dimensions inch(mm) | | | | | | |
|-------------------------------------|--------------------|----------------------------|------------|-------------|------------|-------------|------------|------------|
| | | NEMA Tab | B | L | F | E | D | d1 |
| <i>NEW</i> | 76-IFD22-110 | .032 x .110 (0.8 x 2.8) | .126 (3.2) | .728 (18.5) | .252 (6.4) | .394 (10.0) | .157 (4.0) | .067 (1.7) |
| <i>NEW</i> | 76-IFD22-187 | .032 x .187 (0.8 x 4.8) | .197 (5.0) | .748 (19.0) | .256 (6.5) | .394 (10.0) | .157 (4.0) | .067 (1.7) |
| <i>NEW</i> | 76-IFD22-250 | .032 x .250 (0.8 x 6.4) | .260 (6.6) | .827 (21.0) | .311 (7.9) | .394 (10.0) | .157 (4.0) | .067 (1.7) |
| <i>NEW</i> | 76-IFD16-110 | .032 x .110 (0.8 x 2.8) | .126 (3.2) | .728 (18.5) | .252 (6.4) | .394 (10.0) | .177 (4.5) | .091 (2.3) |
| <i>NEW</i> | 76-IFD16-187 | .032 x .187 (0.8 x 4.8) | .197 (5.0) | .748 (19.0) | .256 (6.5) | .394 (10.0) | .177 (4.5) | .091 (2.3) |
| <i>NEW</i> | 76-IFD16-250 | .032 x .250 (0.8 x 6.4) | .260 (6.6) | .827 (21.0) | .311 (7.9) | .394 (10.0) | .177 (4.5) | .091 (2.3) |
| <i>NEW</i> | 76-IFD12-250 | .032 x .250 (0.8 x 6.4) | .260 (6.6) | .925 (23.5) | .311 (7.9) | .492 (12.5) | .217 (5.5) | .134 (3.4) |

NYLON FULLY INSULATED FEMALE DISCONNECTS

Specifications

- **Maximum Electrical Rating:** 300 Volts
- **Maximum Temperature:** +105°C
- **Terminal Material:** Brass
- **Plating:** Electro Tin Plated
- **Insulated Material:** Easy Entry Nylon

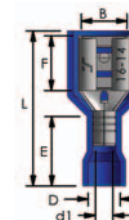

Ordering Information:

| Wire Range AWG / mm ² | NTE Part Number | Dimensions inch(mm) | | | | | | |
|-------------------------------------|--------------------|----------------------------|------------|-------------|------------|-------------|------------|------------|
| | | NEMA Tab | B | L | F | E | D | d1 |
| <i>NEW</i> | 76-NFIFD22 | .032 x .250 (0.8 x 6.4) | .260 (6.6) | .866 (22.0) | .311 (7.9) | .413 (10.5) | .165 (4.2) | .067 (1.7) |
| <i>NEW</i> | 76-NFIFD16 | .032 x .250 (0.8 x 6.4) | .260 (6.6) | .866 (22.0) | .311 (7.9) | .413 (10.5) | .193 (4.9) | .091 (2.3) |
| <i>NEW</i> | 76-NFIFD12 | .032 x .250 (0.8 x 6.4) | .260 (6.6) | .965 (24.5) | .311 (7.9) | .512 (13.0) | .256 (6.5) | .134 (3.4) |