



### Standard Polyethylene Spiral Binding for general applications

#### SBPE


SBPE spiral binding is suitable for standard electrical applications and panel building and plant engineering. Sizes 4 and 9 are also available in practical 5 metre lengths.

#### Features and Benefits


- Organises and protects cables and hoses
- Suitable for retro-fitting
- Cables branch out at any point
- Wide range of diameters and colours



One Step to the Web!

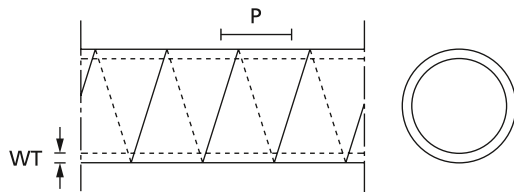

Spiral binding

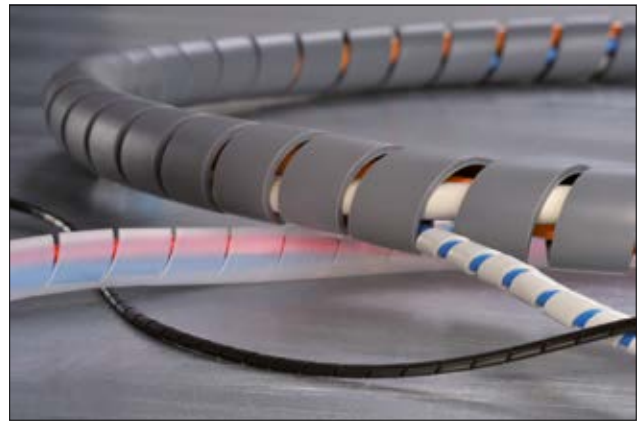

Spiral binding SBPE.

<b>MATERIAL</b>	Polyethylene (PE)
<b>Operating Temperature</b>	-60 °C to +80 °C, intermittent +120 °C
<b>Flammability</b>	UL94 HB



TYPE	Nominal Ø	Wall (WT)	Pitch (P)	Bundle Ø min.	Bundle Ø max.	Colour	Reel Length	Article-No.
SBPE1.5	1.5	0.80	6.0	1.6	8.0	Black (BK)	30 m	161-41001
	1.5	0.80	6.0	1.6	8.0	Grey (GY)	30 m	161-41002
	1.5	0.80	6.0	1.6	8.0	Natural (NA)	30 m	161-41000
SBPE4	4	1.00	7.8	5.0	20.0	Black (BK)	30 m	161-41101
	4	1.00	7.8	5.0	20.0	Grey (GY)	30 m	161-41102
	4	1.00	7.8	5.0	20.0	Natural (NA)	30 m	161-41100
SBPE9	9	1.40	12.5	10.0	100.0	Black (BK)	30 m	161-41201
	9	1.40	12.5	10.0	100.0	Grey (GY)	30 m	161-41202
	9	1.40	12.5	10.0	100.0	Natural (NA)	30 m	161-41200
SBPE16	16	1.60	16.0	20.0	150.0	Black (BK)	30 m	161-41301
	16	1.60	16.0	20.0	150.0	Grey (GY)	30 m	161-41302
	16	1.60	16.0	20.0	150.0	Natural (NA)	30 m	161-41300

All dimensions in mm. Subject to technical changes.  
Minimum Order Quantity (MOQ) may differ from package content.

TYPE	Nominal Ø	Wall (WT)	Pitch (P)	Bundle Ø min.	Bundle Ø max.	Colour	Reel Length	Article-No.
SBPE4D	4	1.00	7.8	5.0	20.0	Black (BK)	5 m	161-41104
	4	1.00	7.8	5.0	20.0	Grey (GY)	5 m	161-41105
	4	1.00	7.8	5.0	20.0	Natural (NA)	5 m	161-41103
SBPE9D	9	1.40	12.5	10.0	100.0	Black (BK)	5 m	161-41204
	9	1.40	12.5	10.0	100.0	Grey (GY)	5 m	161-41205
	9	1.40	12.5	10.0	100.0	Natural (NA)	5 m	161-41203

All dimensions in mm. Subject to technical changes.  
Minimum Order Quantity (MOQ) may differ from package content.