




6012-2Z


Popular item
SKF Explorer

Dimensions

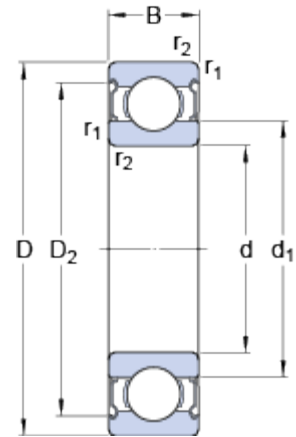

d		2.3622	in
D		3.7402	in
B		0.7087	in
d ₁		2.8071	in
D ₂		3.4055	in
r _{1,2}	min.	0.0433	in

Abutment dimensions

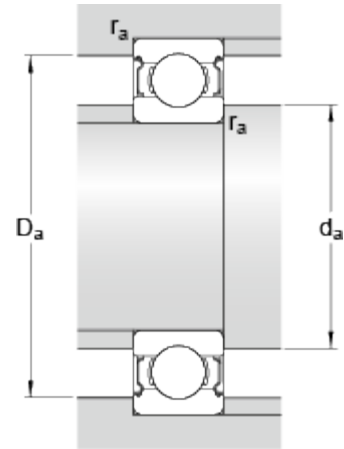

d _a	min.	2.5984	in
d _a	max.	2.8032	in
D _a	max.	3.5039	in
r _a	max.	0.0394	in

Calculation data

Basic dynamic load rating	C	6902	lbf
Basic static load rating	C ₀	5216	lbf
Fatigue load limit	P _u	220	lbf
Reference speed		15000	r/min
Limiting speed		7500	r/min
Calculation factor	k _r	0.025	
Calculation factor	f ₀	15.6	

Mass

Mass bearing	0.95	lbs
--------------	------	-----