

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5055700801](#)
Status: **Active**
Overview: Micro-Lock Plus Wire-to-Board Connector System
Description: Micro-Lock PLUS Receptacle Housing, 2.00mm Pitch, Single Row, with Positive Lock, 8 Circuits, Black

Documents:

Drawing (PDF)	Application Specification 5055700001-A03 (PDF)
Product Specification 5055700001-001 (PDF)	Packaging Specification 5055709200-200 (PDF)
Application Specification 5055700001-A02 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Crimp Housings
Series	505570
Application	Signal, Wire-to-Board
Overview	<u>Micro-Lock Plus Wire-to-Board Connector System</u>
Product Name	Micro-Lock PLUS
UPC	889056572835


Physical

Circuits (maximum)	8
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	448.530/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40°C to +105°C

Material Info

Reference - Drawing Numbers

Application Specification	5055700001-A02, 5055700001-A03
Packaging Specification	5055709200-200
Product Specification	5055700001-001
Sales Drawing	5055700001-000

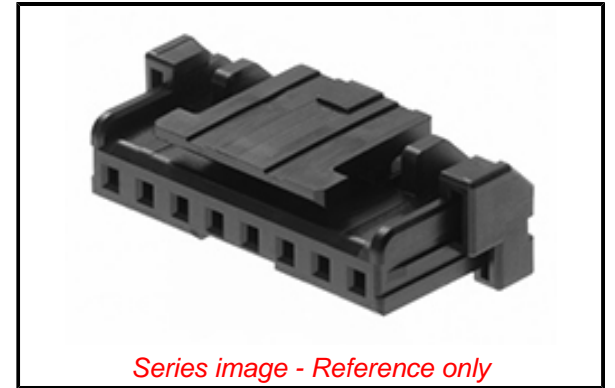

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/01/2018 (15
January 2018)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[505570](#) Series

Mates With

Micro-Lock PLUS Vertical Header [505575](#)

Micro-Lock PLUS Right Angle Header [505578](#)

Use With

Micro-Lock PLUS Terminal [505572](#)