
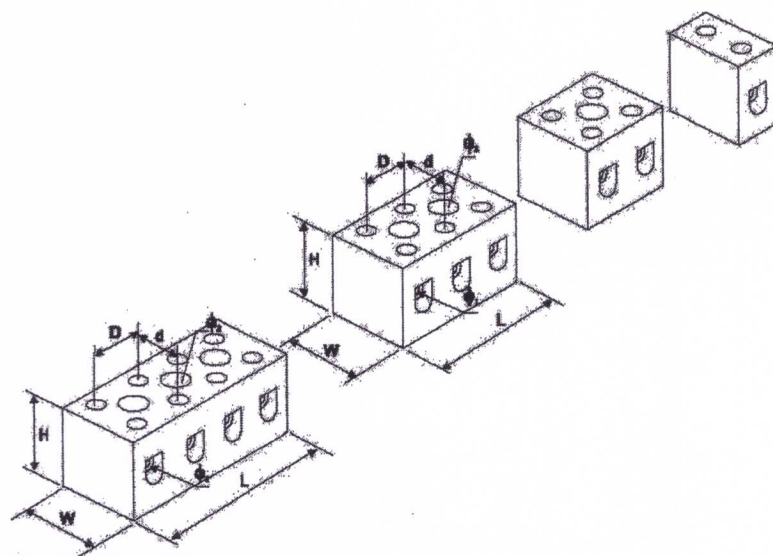


PORCELAIN TERMINAL BLOCKS

CPO TYPE
1 & 2 & 3 & 4 POLES

SPECIFICATIONS

INSERTS: NICKEL PLATED BRASS
HOUSING: PORCELAIN (GLAZED OPTION)
TEMP.: 800°C (HOUSING), 350°C (INSERTS)
SCREWS: GALVANISED STEEL
STANDARD: CE (BS EN 60998)
COLOUR: WHITE
FEATURE: HARD & SOLID
 VERY HIGH TEMPERATURE
 NON-INFLAMMABLE
 RESISTANT TO CHEMICALS

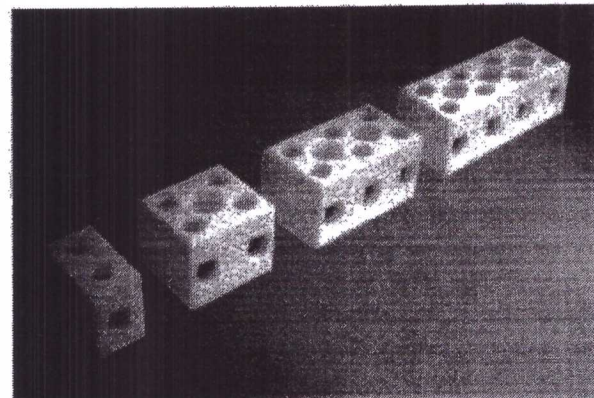

CE

	CROSS SECTION	CURRENT RANGE	RATED VOLTAGE	DIMENSIONS (mm)						
				W	L	Φ ₁	Φ ₂	D	d	H
CPO-5A-1P	4 mm ²	5-32A	450V	13	12	3.2	-	-	8	16
CPO-5A-2P	4 mm ²	5-32A	450V	18	21	3.2	4.5	12	8	16
CPO-5A-3P	4 mm ²	5-32A	450V	18	33	3.2	4.5	12	8	16
CPO-5A-4P	4 mm ²	5-32A	450V	17.8	45.2	3.2	4.8	12	8	15.8
CPO-15A-1P	10 mm ²	15-57A	450V	21	13	4.3	4.8	-	10	20
CPO-15A-2P	10 mm ²	15-57A	450V	21	24	4.3	4.8	14	10	20
CPO-15A-3P	10 mm ²	15-57A	450V	21	36	4.3	4.8	14	10	20
CPO-15A-4P	10 mm ²	15-57A	450V	20.7	48.6	4.3	4.9	13	10	19.5
CPO-30A-1P	16 mm ²	30-76A	450V	27	15	6.1	5.0	-	12	22
CPO-30A-2P	16 mm ²	30-76A	450V	27	31	6.1	5.0	17	12	22
CPO-30A-3P	16 mm ²	30-76A	450V	27	48	6.1	5.0	17	12	22
CPO-30A-4P	16 mm ²	30-76A	450V	26.6	64.3	6.1	4.9	17	12.5	21.3