




SPECIFICATION CONTROL DRAWING Crystal Resonator

FREQUENCY

32.768000kHz

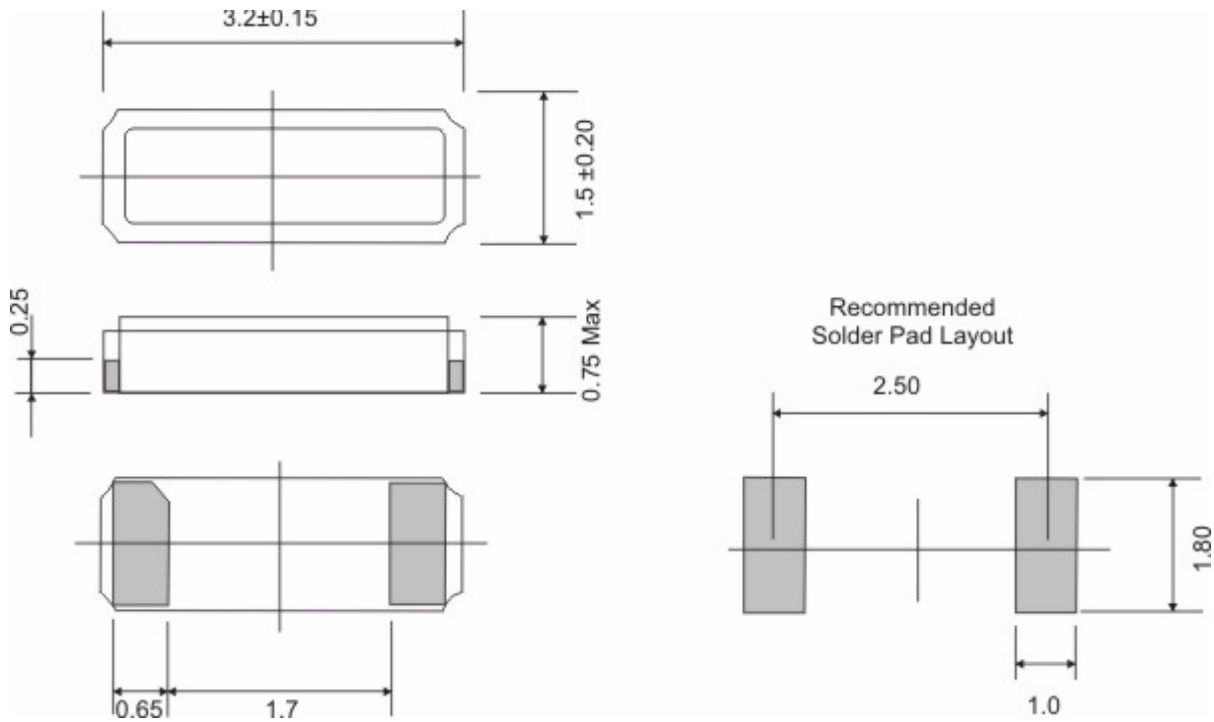

Holder Style	3,2 x 1,5mm
Mode	Fundamental
Adjustment Tolerance	± 20PPM at 25°C
Temperature Stability	± -.034 PPM
Operating Temp. Range	-40°C to +85°C
Load Capacitance	12.5 pF
ESR	70000 Ohm
Drive Level	1.0 uW mW
Ageing	+/-5ppm 1st Year Max
Marking	HxxxCC H=STD, xxx = YWW, CC= Internal code

Amdt Date	Change Note	AEL Code
10 MAR 11	Temp Stab: -0.0034ppm/C^2	X32K768S113
1 AUG 17	Marking Updated	Issue Ref C