


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2042261001](#)
Status: **Active**
Overview: Squba Sealed Wire-to-Wire Connectors
Description: Squba Plug Terminal, Matte Tin Plating, 22-24 AWG

Documents:

Drawing (PDF)	Packaging Specification 2042260000-PK-000 (PDF)
Product Specification 2042200000-PS-000 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification 2042200000-TS-000 (PDF)	Product Literature (PDF)
Application Specification 2042200000-AS-000 (PDF)	

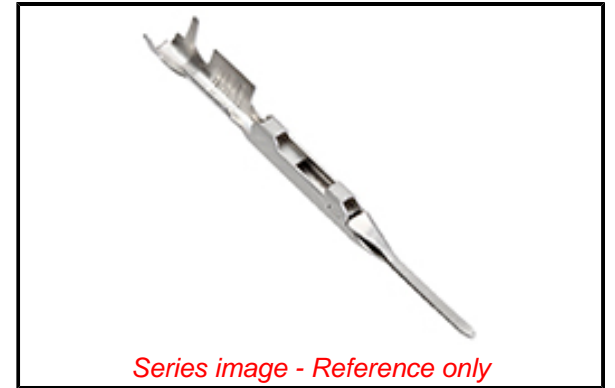

General

Product Family	Crimp Terminals
Series	204226
Application	Signal
Crimp Quality Equipment	Yes
Overview	<u>Squba Sealed Wire-to-Wire Connectors</u>
Product Literature Order No	987651-7401
Product Name	Squba
UPC	191128320627

Physical

Durability (mating cycles max)	10
Gender	Male
Material - Metal	Copper Alloy
Material - Plating Mating	Matte Tin
Material - Plating Termination	Matte Tin
Net Weight	0.010/g
Packaging Type	Reel
Plating min - Mating	2.500µm
Plating min - Termination	2.500µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.95mm-1.40mm
Wire Size AWG	22, 24
Wire Size mm ²	N/A

Electrical

Current - Maximum per Contact	6.0A
Voltage - Maximum	125V

Material Info

Reference - Drawing Numbers

Application Specification	2042200000-AS-000
Packaging Specification	2042260000-PK-000
Product Specification	2042200000-PS-000, 2042200000-TS-000
Sales Drawing	2042260000-SD-000

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[204226](#) Series

Use With

Squba Plug Assembly [204223](#)