




MPN	Description
LWC38-H25-D	WIRE CLIPS - PUSH MOUNT

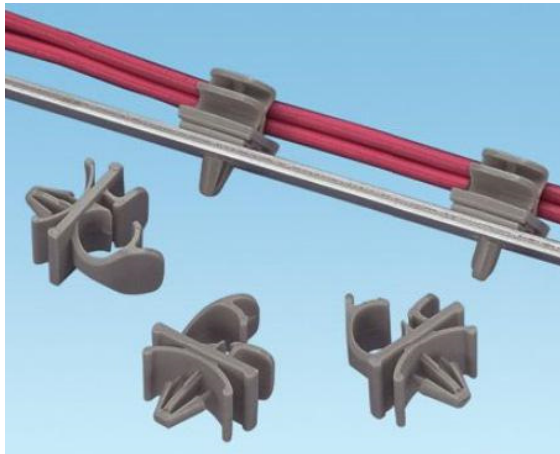

Latching wire clip, push barb mount, .38" (9.7mm) bundle, natural.

Specifications

Mount Method	Push Barb
Overall Length (In.)	NA
Overall Length (mm)	NA
Color	Natural
Material	Nylon 6.6
Overall Width (In.)	0.58

Overall Width (mm)	14.7
Overall Height (In.)	0.57
Overall Height (mm)	14.5
Maximum Bundle Width (In.)	NA
Maximum Bundle Width (mm)	NA
Mounting Hole Diameter (mm)	NA
Maximum Compatible Panel Thickness (In.)	NA
Maximum Compatible Panel Thickness (mm)	NA
Vertical Static Load Capacity (kg)	NA
Vertical Static Load Capacity (lb)	NA
Horizontal Static Load Capacity (kg)	NA
Horizontal Static Load	NA

Capacity (lb)	
Environment	Indoor
UL Recognized	E136577
Length (In.)	0.94
Length (mm)	23.9
Flammability Rating	UL94V-2
Maximum Bundle Diameter (In.)	0.38
Maximum Bundle Diameter (mm)	9.5
Maximum Panel Thickness (In.)	0.11
Maximum Panel Thickness (mm)	2.7
Panel Hole Diameter (In.)	0.22
Panel Hole Diameter (mm)	5.6
Type	Wire Clips - Push Mount

RoHS Compliancy Status	Compliant
---------------------------	-----------