

# K50L Series

## Audible, Easy-to-See Indicator Lights



## Rugged, self-contained bright lights with steady or pulsed audible alarms

K50L EZ-LIGHT® audible job lights are the perfect solution for operator guidance and equipment status indication by providing steady or pulsed audible alarms with bright, intense LEDs. Banner's EZ-LIGHT Indicators are easy-to-install, easy-to-use and cost-effective. Indicators are available in one-, two- or three- color versions.

- ▶ Real-time operational status indication for workers and supervisors
- ▶ Easy-to-see bright, high intensity LEDs with audible alarm
- ▶ Completely self-contained device, no external controller needed
- ▶ Indicators are available in one-, two- and three-color versions with standard green, yellow, and red; contact factory for additional color options
- ▶ IP67 models come with an intensity adjustment
- ▶ IP69K models with fixed low audible intensity are great for food and beverage applications because there are no sound ports to collect liquids and debris
- ▶ Cabled and quick-disconnect models available
- ▶ Immune to EMI and RFI interference

## Bright lights for operator guidance and equipment status



**Tank Level Monitoring Status Indication**  
K50L audible lights visibly and audibly alert operators when tank is filled to a certain point to prevent overflow.



**Product Line Status Indication**  
Bright domed lights indicate the status of the workstations by alerting operators when products are complete.



**Manufacturing Line Blockage Indication**  
A red, audible domed light alerts operators of congestion due to a box pile up.

### 40-plus years of sensor design experience, quality control, sales support and cost-effective solutions:

- ▶ Banner quality products with global availability
- ▶ Rapid customization with most products shipping in 3 days or less
- ▶ Industry's largest force of application engineers to solve your toughest challenges
- ▶ More than 3,000 factory and local field representatives to serve you

[www.bannerengineering.com](http://www.bannerengineering.com)

1.888.373.6767

**BANNER®**


more sensors, more solutions

[bannerengineering.com](http://bannerengineering.com)

# EZ-LIGHT K50L Series Audible Indicators

## Dimensions

	Models*	Environmental Rating	LED**	Connection	Supply Voltage	Audible Tone	Input
Audible	K50LGRA1YPQ	IP50	3 Color: Green, Red, Yellow	5-pin Euro QD	18 to 30V dc	Steady (75 dB @1 m)	PNP
	K50LGRA1YNQ						NPN
	K50LGRA2YPQ					PNP	
	K50LGRA2YNQ						NPN
	K50LGRAL1YPQ					PNP	
	K50LGRAL1YNQ						NPN
Fixed Audible Sealed	K50LGXASXPQ	IP69K	1 Color: Green	5-pin Euro QD	12 to 30V dc	Steady (65 dB @1 m)	PNP
	K50LGRASXPQ		2 Color: Green, Red				
	K50LGRASYPQ		3 Color: Green, Red, Yellow				
Adjustable Loud Audible Sealed	K50LGXALXPQ	IP67	1 Color: Green	5-pin Euro QD	12 to 30V dc	Loud Steady with volume adjustment (94 dB @1 m)	PNP
	K50LGRALXPQ		2 Color: Green, Red				
	K50LGRALSYPQ		3 Color: Green, Red, Yellow				

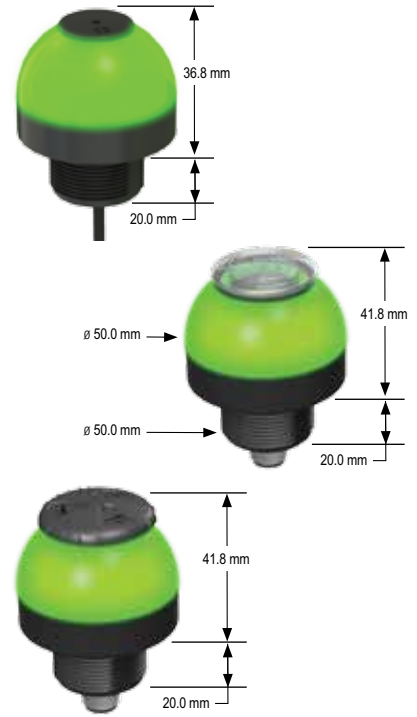

- \* Integral QD models are listed  
 • For 150 mm PVC pigtail with QD, replace Q with QP in model number (example, **K50LGXASXPQP**)  
 • For 2 m (6.5') cable, omit suffix Q from model number (example, **K50LGXASXP**)  
 • A model with a QD requires a mating cable

\*\* Contact factory for other colors and color combinations



For technical information


## Quick-Disconnect (QD) Cordsets

### 8-Pin M12/Euro-Style

	Models		Length
	Straight	Right-Angle	
	MQDC1-506	MQDC1-506RA	2 m
	MQDC1-515	MQDC1-515RA	5 m
	MQDC1-530	MQDC1-530RA	9 m

## Mounting Accessories

### Elevated Use—Standoff Pipe and Adaptors

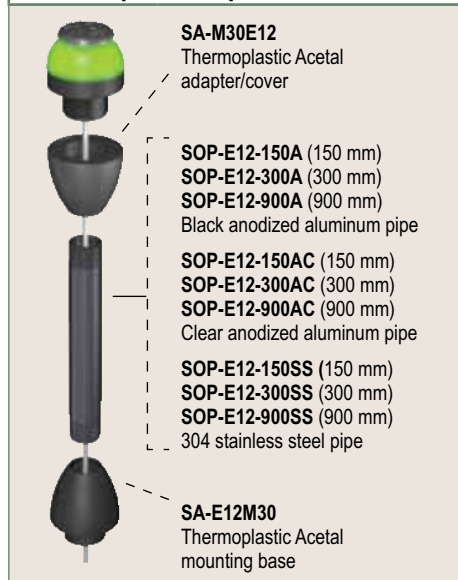

## Brackets

	Model		Model
	<b>SMB30A</b> • Right-angle bracket with curved slot for versatile orientation • 12-ga. stainless steel		<b>SMBAMS30P</b> • Flat bracket • 12-ga. cold-rolled steel
	<b>SMB30FA</b> • Swivel bracket with tilt and pan movement • Easy sensor mounting to extruded rail T-slot		<b>SMBAMS30PL52</b> • Flat bracket with space for 70 x 40 mm label • 12-ga. cold-rolled steel
	<b>SMB30MM</b> • 12-ga. stainless steel bracket with curved mounting slots		<b>SMBAMS30PL52R</b> • Flat bracket with space for 60 x 58 mm label • 12-ga. cold-rolled steel
	<b>SMB30Q</b> • Right-angle flanged mounting bracket with curved slot • 12-ga. stainless steel		<b>SMBAMS30RA</b> • Right-angle bracket • 12-ga. cold-rolled steel
	<b>SMB30RAVK</b> • V-clamp, right-angle bracket and fasteners for mounting to pipe or extrusions • Clamp accommodates 28 mm dia. tubing or 1" square extrusion		<b>SMBAMS30RLJ</b> • Right-angle bracket with 70 x 40 mm space for label • 12-ga. cold-rolled steel
	<b>SMB30SC</b> • Black reinforced thermoplastic polyester swivel bracket • Stainless steel mounting and swivel locking hardware included		<b>SMBAMS30RLS</b> • Right-angle bracket with 62 x 26 mm space for label • 12-ga. cold-rolled steel