


Vintage 30



Back in 1986 a new breed of hard rock player was on the rise. To meet the demands of the players and their increasingly 'hot-rodded' amplifiers, we set out to develop a modern guitar speaker, capable of handling much more power and overdrive. To achieve this, we coupled our 'H' magnet (the closest in performance to Alnico) with a new cone and voice coil employing contemporary materials.Our most revealing speaker, the Vintage 30 features enormously detailed and complex overtones, a warm low-end, a famously rich vocal mid-range and a beautifully detailed top-end. Used singly to reveal the complexities in hand- wired boutique amps, or in quartets for a wonderfully intricate vintage 3D crunch, the Vintage 30 sound has been captured on thousands of recordings from a diverse range of notable players including Slash, Steve Stevens and Peter Frampton.

8 Ω Frequency Response

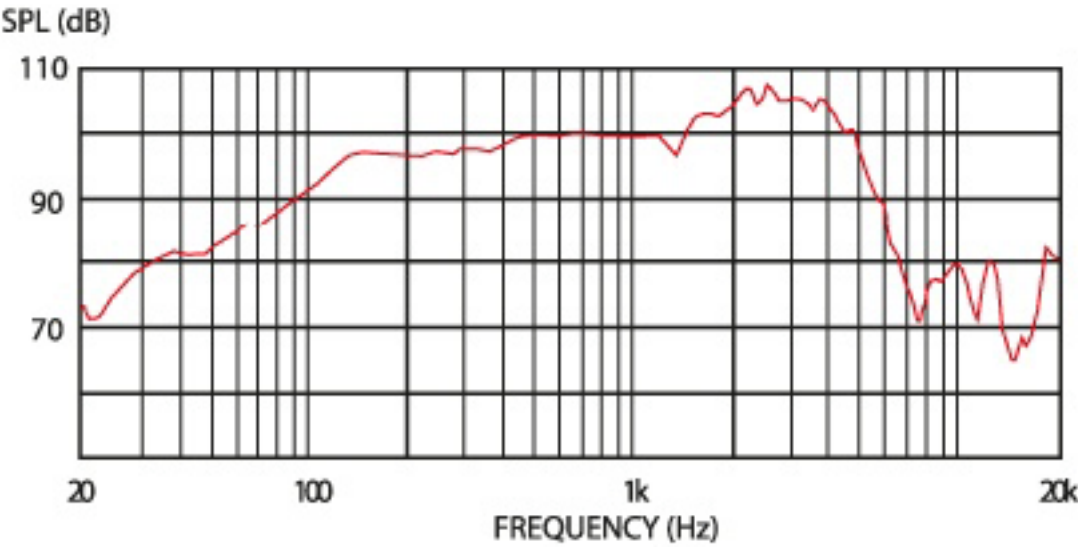

General Specifications

Nominal diameter	12", 305mm
Power rating	60Wrms
Nominal impedance	Available 8 Ω or 16 Ω
Sensitivity	100dB
Chassis type	Pressed steel
Voice coil diameter	1.75", 44.5mm
Voice coil material	Round copper
Magnet type	Ceramic
Magnet weight	50oz, 1.42kg
Frequency range	70-5000Hz
Resonance frequency, Fs	75Hz
DC resistance, Re	Available 7.3 Ω or 12.9 Ω

Mounting Information

Cut-out diameter	11.1", 283mm
Diameter	12.2", 309mm
Magnet structure diameter	6.1", 156mm
Mounting slot dimensions	0.31", 7.9mm Ø
Mounting slot PCD	11.7", 297mm
Number of mounting slots	4
Overall depth	5.3", 135mm
Unit weight	10.4lb, 4.7kg