


EKL S 1275-CMG

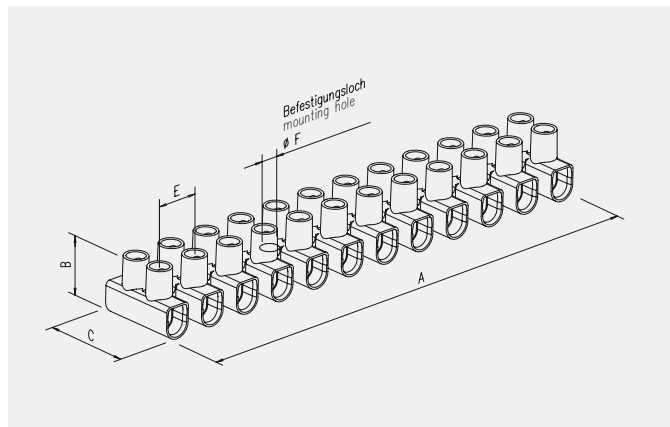

Nominal voltage		450 V
Clamping range	EKL 0 S	1 - 4 mm ² solid wires 1 - 2.5 mm ² rigid stranded and flexible wires 1,5 - 6 mm ² 2.5 - 10 mm ² solid wires 2.5 - 6 mm ² rigid stranded and flexible wires 4 - 16 mm ² solid wires 4 - 10 mm ² rigid stranded wires 4 - 6 mm ² flexible wires
Wire stripping length	EKL 0 S	5 + 1 mm 6 + 1 mm 7.5 + 1 mm 8.5 + 1 mm
Max. ambient temp.	EN 60998	T80
Material	Terminal housing	Polypropylene
	Inserts	Tinned steel
	Screws	Galvanized steel

EKL .. S	Gewindedimension Dimension of thread	Farbe Colour	Art. Nummer Art. number	VPE / Stk. Packing / pcs.	Gewicht / Stk. Weight / pc. in g	Kart. Type Box type	Breite Width A in mm	Höhe Height B in mm	Tiefe Depth C in mm	Teilung Pitch E in mm	Befestigungsloch mounting hole F in mm	* in 10er Packs *in packs of 10
EKL 0 S	M2,6	weiß white	88717768	50 x 10*	17,3	C	94,9	13	16,6	8,1	2,65	x

Prüfzeichen | Approvals    



 EKL 0 S 0,6 x 3,5 | 0,4 Nm EKL 2 S 0,8 x 4,5 | 0,8 Nm
EKL 1 S 0,8 x 4,0 | 0,5 Nm EKL 3 S 0,8 x 4,5 | 1,2 Nm