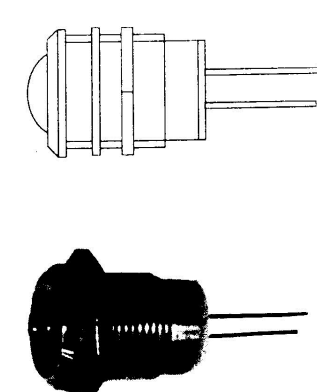
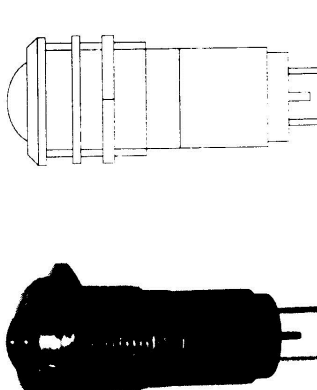


Led Signalleuchten Einbaudurchmesser 14 mm
Led Indicators Body diameter 14 mm

Standardhelligkeit
Standard brightness

Bestell-Nr.	Farbe	V _{OP} +10% (V)	I _{OP max.} (mA)	V _F (V)	I _{V typ.} (mcd) *I _F = 20mA	I _{F max.} (mA)	Abb.	Abmessungen, siehe Zeichnungsnr. Dimensions, see Drawing No.	19210-A	A
Part No.	Colour	(V)	(mA)	(V)			Illu.			
1921*000	Super rot Super red			2,0/2,5	*20	30	A			
1921*001	Grün Green			2,2/2,5	*20	30	A			
1921*002	Gelb Yellow			2,1/2,5	*23	30	A			
1921*003	Hyper rot Hyper red			1,85/2,5	*65	30	A			
1921*050	Super rot Super red			2,0/2,5	*20	30	B			
1921*051	Grün Green			2,2/2,5	*20	30	B			
1921*052	Gelb Yellow			2,1/2,5	*23	30	B			
1921*053	Hyper rot Hyper red			1,85/2,5	*65	30	B			
1921*150	Super rot Super red	6	30		32		B		19210-B	B
1921*151	Grün Green	6	30		30		B			
1921*152	Gelb Yellow	6	30		35		B			
1921*153	Hyper rot Hyper red	6	30		90		B			
1921*250	Super rot Super red	12	30		32		B			
1921*251	Grün Green	12	30		30		B			
1921*252	Gelb Yellow	12	30		35		B			
1921*253	Hyper rot Hyper red	12	30		90		B			
1921*350	Super rot Super red	24	22		22		B			
1921*351	Grün Green	24	22		22		B			
1921*352	Gelb Yellow	24	22		25		B			
1921*353	Hyper rot Hyper red	24	22		70		B			
Led Signalleuchten mit höherer Helligkeit siehe Seite 26!								For higher brightness see page 26!		
Arbeitstemperatur (T _{OP}): -55°C - +70°C Lagertemperatur (T _{STG}): -55°C - +100°C * Die Signalleuchte kann mit Glanzchrom oder Schwarzchrom geliefert werden. Die 5. Stelle der Bestellnummer wird mit 0 oder 1 codiert. Glanzchrom = 0 Schwarzchrom = 1 Beispiel: 19210000 super rot mit Glanzchrom 19211000 super rot mit Schwarzchrom								Operating temperature (T _{OP}): -55°C - +70°C Storage temperature (T _{STG}): -55°C - +100°C * The Led indicator can be delivered in bright or black chrome reflector. The 5. digit has to be coded with 0 or 1. Bright chrome = 0 Black chrome = 1 Example: 19210000 super red with bright chrome 19211000 super red with black chrome		
Led Signalleuchten mit anderen Spannungen auf Anfrage Technische Änderungen vorbehalten								Led Indicators with other voltages upon request Specification subject to change without notice		