



### Model No. 140703EURD

Set of no. 703 straight bar hasp + no. 140 brass padlock

#### Best Used For:



Cabinets



Industrial,  
Storefront &  
Business Gates



Residential Gates &  
Fences



Sheds, Workshops  
& Garages

#### Security Level:



Basic to medium  
security:

Generally recommended for  
indoor general purpose

## Overview & Features

### Product Features


- Set of a straight bar hasp and a solid brass padlock
- 89mm hard wrought steel body
- Zinc plated hardened steel for added strength and weatherability
- Hardened steel staple resist cutting and sawing
- Hardened steel locking eye for strong cut resistance
- Tamper proof hinge for pry resistance
- 40mm wide solid brass body padlock
- 6mm diameter hardened steel shackle for strong bolt-cutter resistance
- 4-pin cylinder for strong pick resistance
- Mounting hardware included for easy installation

### Product Details

The Master Lock No. 140703EURD features a 40mm Keyed Brass Padlock with 89mm Hasp made of zinc plated hard wrought steel for strength and corrosion resistance. The hardened steel staple and locking eye resist cutting and sawing. The 6mm diameter shackle of the lock is made of nickel plated hardened steel, offering resistance to cutting and sawing. The Limited Lifetime Warranty provides peace of mind from a brand you can trust.

Product Specifications

Product Number	140703EURD
Shackle Dimensions	A: 6mm B: 22mm C: 21mm
Description	Keyed Different, Retail Carded Packaging
Shelf Pack Qty	4
Master Carton Qty	24

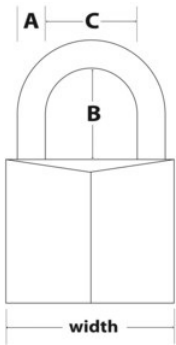

Master Lock Europe S.A.S.

10 avenue de l'arche - Le Colisée Gardens, bâtiment A - 92 400 Courbevoie - La Défense - France  
O:+33-1-41437200 | F:+33-1-41437204  
[www.masterlock.eu](http://www.masterlock.eu)