


AIR CURTAIN
PEL00925



Features:

- Ceiling or wall mounting (vertical or horizontal)
- c/w easy fix bracket
- 3 switched controls for fan only and 2 heat settings
- 2 heat settings (1500W and 3000W)
- Pressed steel epoxy coated body

Installation:

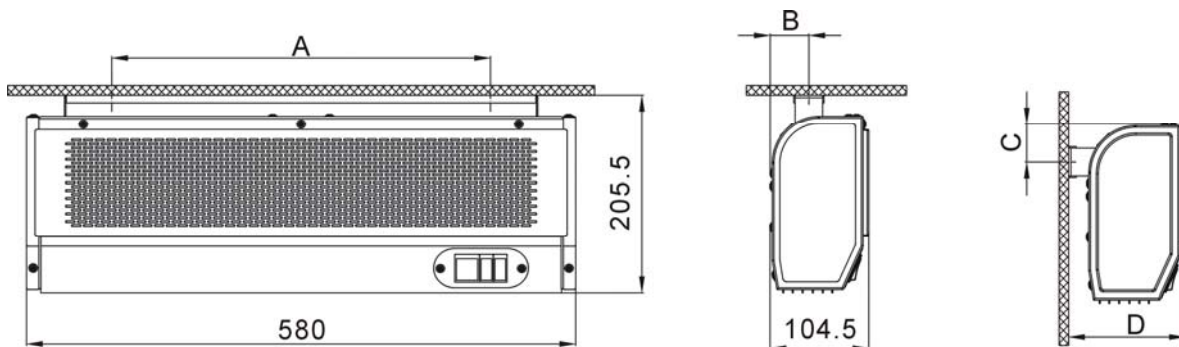

Specifications:

Voltage: 240V~/50Hz, Class I

Rated Power: 3000W

Air Volume: 254m³/hrs

Air Velocity(max): 4.8m/sec

Noise Level: 60dB

Net Weight: 5.2Kg

Packing:

Dimension: 620×155×230mm

Gross Weight: 5.9Kg